

172193-1 ✓ ACTIVE




AMP | Econoseal, Econoseal J - Mark II

TE Internal #: 172193-1

Facial Seal, Black, .079 – .134 in [2 – 3.4 mm] Insulation Diameter, -30 – 105 °C [-22 – 221 °F] Operating Temperature, Econoseal J - Mark II

[View on TE.com >](#)

[Connectors >](#) [Connector Accessories >](#) [Connector Seals & Cavity Plugs](#)

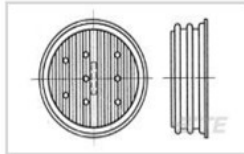

Connector Seal & Plug Type: **Facial Seal**

Primary Product Color: **Black**

Compatible Insulation Diameter Range: 2 – 3.4 mm [.079 – .134 in]

Operating Temperature (Max): 65 °C, 70 °C, 75 °C, 80 °C, 85 °C, 90 °C, 100 °C, 105 °C [149 °F, 158 °F, 167 °F, 176 °F, 185 °F, 194 °F, 212 °F, 221 °F]

Operating Temperature Range: -30 – 105 °C [-22 – 221 °F]

## Features

### Product Type Features

Connector Seal & Plug Type	Facial Seal
----------------------------	-------------

### Body Features

Primary Product Color	Black
-----------------------	-------

### Dimensions

Compatible Insulation Diameter Range	2 – 3.4 mm [.079 – .134 in]
--------------------------------------	-----------------------------

### Usage Conditions

Operating Temperature (Max)	65 °C, 70 °C, 75 °C, 80 °C, 85 °C, 90 °C, 100 °C, 105 °C [149 °F][158 °F][167 °F][176 °F][185 °F][194 °F][212 °F][221 °F]
Operating Temperature Range	-30 – 105 °C [-22 – 221 °F]

### Packaging Features

Packaging Quantity	500
Packaging Method	Bag

## Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant