




Connectors > Connector Accessories > Connector Backshells > DEUTSCH DRC Backshells

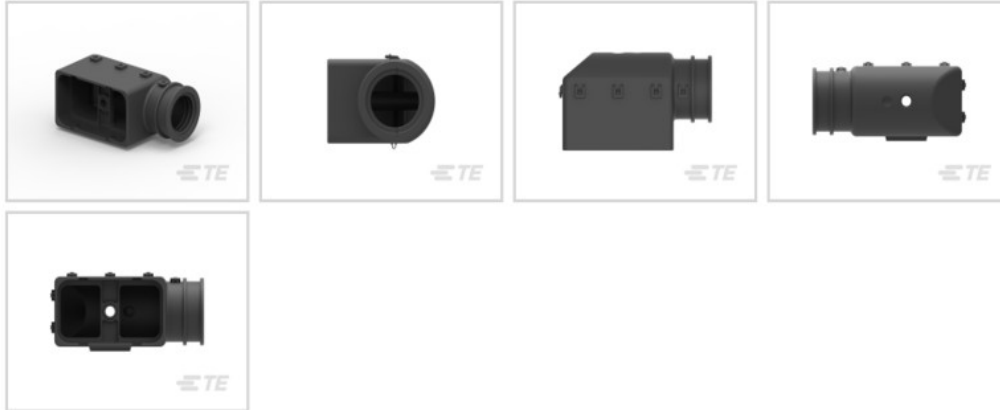

Connector Backshell Product Type: **Backshell**

Primary Product Material: **PA GF**

Number of Positions: **60**

Sealable: **No**

Operating Temperature Range: **-55 – 125 °C [-67 – 257 °F]**

[All DEUTSCH DRC Backshells \(6\)](#)

Features

Product Type Features

Connector Backshell Product Type	Backshell
Sealable	No

Configuration Features

Number of Positions	60
---------------------	----

Body Features

Primary Product Color	Black
Primary Product Material	PA GF

Dimensions

Compatible Cable Diameter Range	0 – 26 mm[0 – 1.024 in]
---------------------------------	-------------------------

Usage Conditions

Operating Temperature (Max)	125 °C[257 °F]
Operating Temperature Range	-55 – 125 °C[-67 – 257 °F]

Industry Standards