




Connectors > Connector Accessories > Connector Caps & Covers

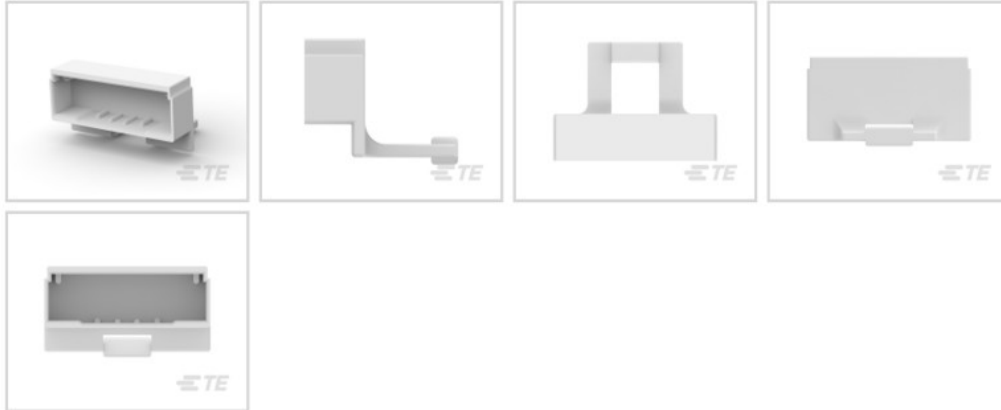

Connector Cover Type: **Dust Cover**

Operating Temperature (Max): 105 °C [221 °F]

Sealable: **No**

Operating Temperature Range: -40 – 105 °C [-40 – 221 °F]

Features

Product Type Features

| | |
|----------------------|------------|
| Connector Cover Type | Dust Cover |
| Sealable | No |

Housing Features

| | |
|---------------------------------|-------------|
| Compatible With Connector Shape | Rectangular |
|---------------------------------|-------------|

Usage Conditions

| | |
|-----------------------------|----------------------------|
| Operating Temperature (Max) | 105 °C[221 °F] |
| Operating Temperature Range | -40 – 105 °C[-40 – 221 °F] |

Packaging Features

| | |
|--------------------|-----|
| Packaging Quantity | 200 |
| Packaging Method | Bag |

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

| | |
|-----------------------------------------------|-----------------------------------------|
| EU RoHS Directive 2011/65/EU | Compliant |
| EU ELV Directive 2000/53/EC | Compliant |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold |