


AXEL

3M Company

2-9689-01 Socket 355056080A00GF Gray 35505-6080-A00GF

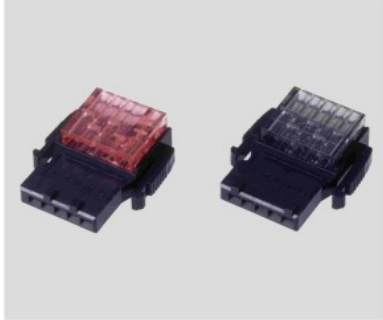

Order No.	2-9689-01
Model No.	35505-6080-A00GF
JAN Code	0000000000000
	JPY: 890
	USD: 5.95
Standard price	
	Exchange rate 1USD= 149.64JPY
	Valid price in Japan
Quantity	1piece

Spec

- Material: Body/nylon resin, Cover/PC (polycarbonate), Contact/copper alloy
- Applicable product: Connector/power clamp (mounting plug for repeater connections: 2-9690-01)
- Rating voltage: AC/DC250V or less
- Rated current: Maximum 10A/pole (however, When energizing the adjacent contact 2 poles or more up to 7A/pole)
- Operating temperature, humidity range: -20 - 75°C, 85%RH or less
- Cover color: Gray
- Applicable wire (AWG No.): 18
- Insulation coated outer diameter (φmm): 2.2 - 3.0
- 5 pole
- Model number: 35505-6080-A00GF

▶ Package size : 30×30×10 mm 100 g

Product Catalog

Catalog Name	Page
AS ONE Catalog 2015 [Instruments for Laboratory]	1630