


# AXEL

Kokusai Chart Corporation

## 1-5514-11 Thermo-Hygro Recorder For 8 Days KC10-WW

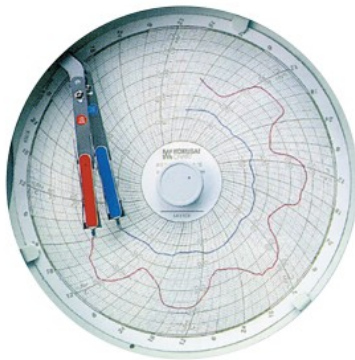

Order No. 1-5514-11  
Model No. KC10-WW  
JAN Code 0000000000000

 
**JPY:**  
**35,000**  
**USD:**  
**233.90**

Standard price

Exchange rate 1USD= 149.64JPY

Valid price in Japan

Quantity 1piece



### Features

- Temperature is recorded in red, humidity in blue. Difference can be recognized at glance.
- Recording data for continuous 8days is available with 1 paper.

### Spec

- Model number: KC10-WW
- Recording time: 8 days/rotation
- Size: 200 x 60 x 200mm
- Weight: Approx 650g
- Accessories: Recording paper (165mmφ) x 30 sheets, pen (red, blue) x 1 each
- Temperature: Measurement range/-10 to +40°C, Scale units/1°C, Accuracy +/- 2°C, Internal sensor/bimetal, Pen color/red
- Relative humidity: Measurement range/0 - 100%RH, Scale unit/2% RH, Accuracy/+/- 5% RH (30 - 90% RH or less), Internal sensor/nylon film, Pen color/blue
- Shape: Wall hanging type automatic writing
- Power supply: Manganese AA dry cell x 1 volume (included for test)

▶ Package size : 200×200×60 mm 650 g

### Product Catalog

| Catalog Name                                     | Page |
|--|------|
| AS ONE Catalog 2023 [Instruments for Laboratory] | 649  |
| AS ONE Catalog 2021 [Instruments for Laboratory] | 609  |
| AS ONE Catalog 2019 [Instruments for Laboratory] | 575  |
| AS ONE Catalog 2017 [Instruments for Laboratory] | 454  |
| AS ONE Catalog 2015 [Instruments for Laboratory] | 417  |