


ACRYLIC RESIN LEVEL

Special Orders
Available

Please request for a quote.

R Circular Acrylic Resin LevelSpecial Orders
Available

Simple and easy application to various machinery
Sensitivity 91/2mm *R-25 : Sensitivity 69/2mm

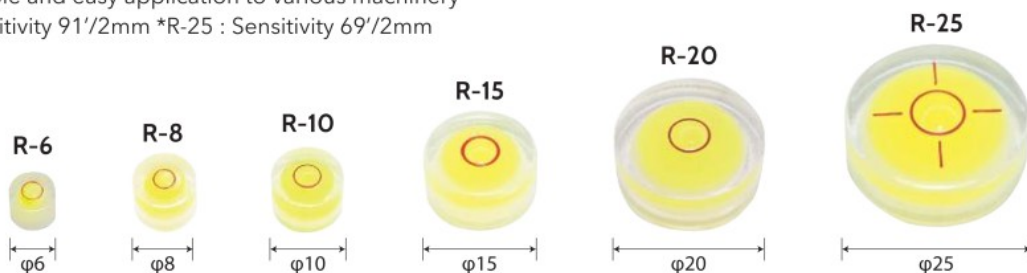**Special order examples**

The following option fees may be quoted separately.

- Change vial diameter
- Change color of red scale line
- Change body size
- Change radius of curvature
- Change liquid color to transparent

Circular Acrylic Resin Level

Product No.	Size	Vial Diameter	Scale Diameter	Weight	Quantity per Carton	Retail Price	JAN Code
R-6	φ6×5mm	3.5mm	2.5mm	0.18g	1	1,040yen	4 993711 581011
R-8	φ8×6.5mm	5mm	2.5mm	0.35g	1	1,010yen	4 993711 581028
R-10	φ10×7mm	7mm	3.5mm	0.6g	1	960yen	4 993711 581035

Product No.	Size	Vial Diameter	Scale Diameter	Weight	Quantity per Carton	Retail Price	JAN Code
R-15	φ15×8mm	10mm	4mm	1.4g	10	880yen	4 993711 581042
R-20	φ20×8mm	14mm	5mm	2.5g	10	860yen	4 993711 581059
R-25	φ25×8.5mm	18mm	6.5mm	4g	10	960yen	4 993711 581066

*Minimum order quantity:1

RM Circular Magnetic Acrylic Resin LevelSpecial Orders
Available

Easy application with magnet
Sensitivity 91/2mm *RM-25 : Sensitivity 69/2mm

Magnet on
measuring surface**Special order examples**

The following option fees may be quoted separately.

- Change vial diameter
- Change color of red scale line
- Change body size
- Change radius of curvature
- Change liquid color to transparent

Circular Magnetic Acrylic Resin Level


Product No.	Size	Vial Diameter	Scale Diameter	Weight	Quantity per Carton	Retail Price	JAN Code
RM-10	φ10×8mm	7mm	3.5mm	1g	10	1,010yen	4 993711 580212
RM-15	φ15×9mm	10mm	4mm	2g	10	910yen	4 993711 580229

Product No.	Size	Vial Diameter	Scale Diameter	Weight	Quantity per Carton	Retail Price	JAN Code
RM-20	φ20×9mm	14mm	5mm	4g	10	910yen	4 993711 580236
RM-25	φ25×9.5mm	18mm	6.5mm	6g	10	1,010yen	4 993711 580243

*Minimum order quantity:1

Inc-R Circular Acrylic Resin Level with GoniometerSpecial Orders
Available

Circular acrylic resin level with goniometer!

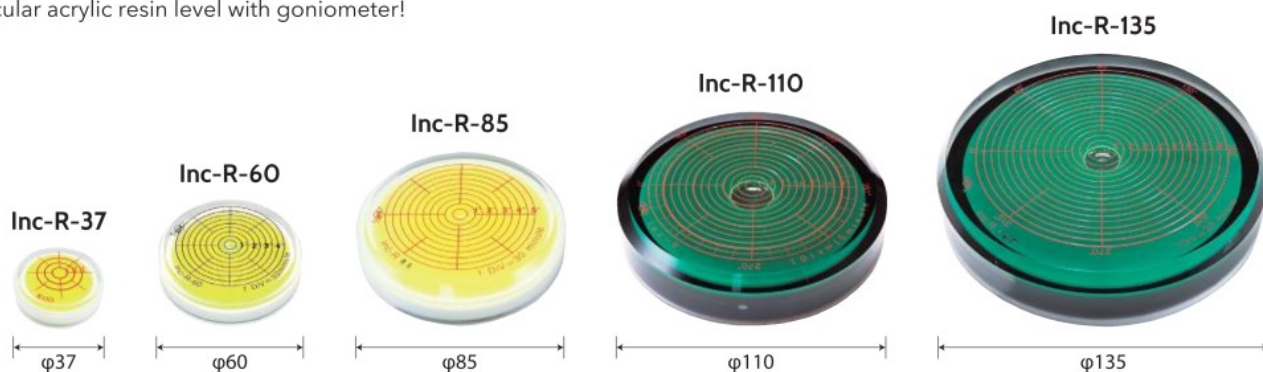

Circular Acrylic Resin Level with Goniometer

Product No.	Size	Measuring Range	Vial Diameter	Weight	Quantity per Carton	Retail Price	JAN Code
Inc-R-37	φ37×12mm	0° to ±3°	27mm	14g	1	5,430yen	4 993711 580977
Inc-R-60	φ60×14mm	0° to ±4°	50mm	39g	1	5,720yen	4 993711 581875
Inc-R-85	φ85×19mm	0° to ±5°	72mm	107g	1	7,150yen	4 993711 081788
Inc-R-110	φ110×23mm	0° to ±3°	92mm	222g	1	10,010yen	4 993711 081795
Inc-R-135	φ135×27mm	0° to ±8°	114mm	410g	1	14,300yen	4 993711 081801

Special order examples

The following option fees may be quoted separately.

- Change color of red scale line
- Change angle value
- Change liquid color to transparent