


エースジョイント


SUS304

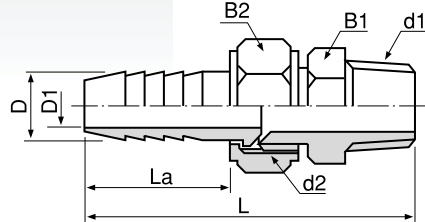

品番	寸法 (mm)							
	d1	φD	φD1	B1	B2	d2	La	L(約)
HS-7107	PT1/8	7	4	12	12	PF1/8	20	44
HS-7208	PT1/4	8	5	14	16	PF1/4	24	57
HS-7209	PT1/4	9	5	14	16	PF1/4	24	57
HS-7310	PT3/8	10.5	7	17	19	PF3/8	25	60
HS-7414	PT1/2	14	10.5	22	24	PF1/2	27	69
HS-7416	PT1/2	16	11.5	22	24	PF1/2	27	69
HS-7620	PT3/4	20.5	15	29	30	PF3/4	33	80

内ネジ・エースニップル

SUS304

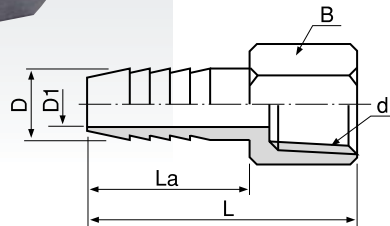


品番	寸法 (mm)					
	d	φD	φD1	B	La	L(約)
HF-7207	PT1/4	7	4	17	26	45
HF-7209	PT1/4	9	5	17	26	45
HF-7210	PT1/4	10.5	7	17	26	45
HF-7310	PT3/8	10.5	7	22	28	49
HF-7314	PT3/8	14	10	22	28	49
HF-7410	PT1/2	10.5	7	24	29	54
HF-7414	PT1/2	14	10	24	29	54

フレキ用ニップル

SUS304




品番	寸法 (mm)				
	d1	d2	φD1	B	L
PN-7044	PF1/2	PT1/2	13	22	30
PN-7066	PF3/4	PT3/4	18	27	34

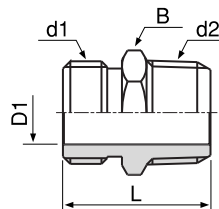

フレキチューブ用袋ナット

SUS304

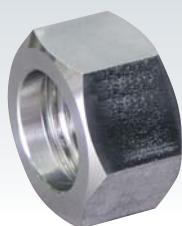

品番	寸法 (mm)			
	d	φD0	B	L
PH-7N04	PF1/2	16.3	24	14
PH-7N06	PF3/4	20.4	30	15

