
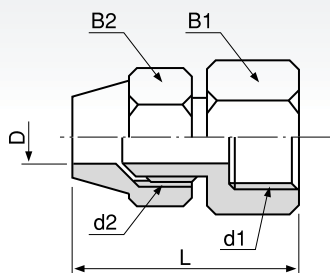


# ゲージフィッティング

C3604BD

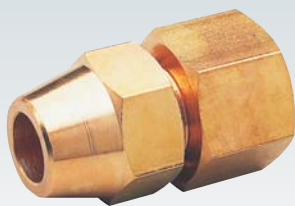


品番	取付ネジ	適用管外径	寸法 (mm)			
	d1	φ D	B1	B2	d2	L(約)
FG-1206	PF1/4	6	17	16	UNF7/16×20	37
FG-1202	PF1/4	6.35	17	16	UNF7/16×20	37
FG-1208	PF1/4	8	17	17	UNF1/2 ×20	37
FG-1203	PF1/4	9.53	17	21	UNF5/8 ×18	37
FG-1210	PF1/4	10	17	21	UNF5/8 ×18	37
FG-1306	PF3/8	6	21	16	UNF7/16×20	39
FG-1302	PF3/8	6.35	21	16	UNF7/16×20	39
FG-1308	PF3/8	8	21	17	UNF1/2 ×20	39
FG-1303	PF3/8	9.53	21	21	UNF5/8 ×18	39
FG-1310	PF3/8	10	21	21	UNF5/8 ×18	39

# フレアエルボ

C3604BD

C3771BD

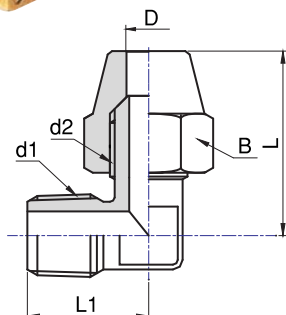

品番	取付ネジ	適用管外径	寸法 (mm)			
	d1	φ D	B	d2	L1	L(約)
FL-1106	PT1/8	6	16	UNF7/16×20	19	29
FL-1102	PT1/8	6.35	16	UNF7/16×20	19	29
FL-1108	PT1/8	8	17	UNF1/2 ×20	19	29
FL-1103	PT1/8	9.53	21	UNF5/8 ×18	21	32
FL-1110	PT1/8	10	21	UNF5/8 ×18	21	32
FL-1206	PT1/4	6	16	UNF7/16×20	22	29
FL-1202	PT1/4	6.35	16	UNF7/16×20	22	29
FL-1208	PT1/4	8	17	UNF1/2 ×20	22	29
FL-1203	PT1/4	9.53	21	UNF5/8 ×18	24	32
FL-1210	PT1/4	10	21	UNF5/8 ×18	24	32
FL-1212	PT1/4	12	24	UNF3/4 ×16	28	40
FL-1204	PT1/4	12.7	24	UNF3/4 ×16	28	40
FL-1306	PT3/8	6	16	UNF7/16×20	25	31
FL-1302	PT3/8	6.35	16	UNF7/16×20	25	31
FL-1308	PT3/8	8	17	UNF1/2 ×20	25	31
FL-1303	PT3/8	9.53	21	UNF5/8 ×18	25	32
FL-1310	PT3/8	10	21	UNF5/8 ×18	25	32
FL-1312	PT3/8	12	24	UNF3/4 ×16	28	40
FL-1304	PT3/8	12.7	24	UNF3/4 ×16	28	40
FL-1406	PT1/2	6	16	UNF7/16×20	29	36
FL-1402	PT1/2	6.35	16	UNF7/16×20	29	36
FL-1408	PT1/2	8	17	UNF1/2 ×20	29	36
FL-1403	PT1/2	9.53	21	UNF5/8 ×18	29	37
FL-1410	PT1/2	10	21	UNF5/8 ×18	29	37
FL-1412	PT1/2	12	24	UNF3/4 ×16	29	40
FL-1404	PT1/2	12.7	24	UNF3/4 ×16	29	40
FL-1415	PT1/2	15	27	UNF7/8 ×14	32	48
FL-1405	PT1/2	15.88	27	UNF7/8 ×14	32	48
FL-1615	PT3/4	15	27	UNF7/8 ×14	34	48
FL-1605	PT3/4	15.88	27	UNF7/8 ×14	34	48
FL-1606	PT3/4	19.05	32	UNS11/16×14	34	52