


## 内ネジエルボ

C3771BD

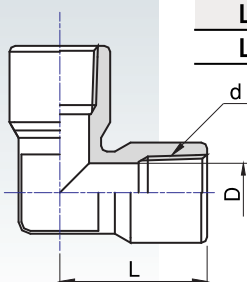


品番	取付ネジ		寸法 (mm)	
	d	$\phi D$	L	
LF-1011	PT1/8	4	22	
LF-1022	PT1/4	8	25	
LF-1033	PT3/8	10	29	
LF-1044	PT1/2	13	34	
LF-1066	PT3/4	19	48	

R

## 異径内ネジエルボ

C3771BD

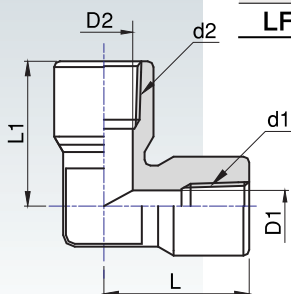

品番	取付ネジ		寸法 (mm)			
	d1	d2	$\phi D1$	$\phi D2$	L1	L
LF-1012	PT1/8	PT1/4	4	8	25	25
LF-1023	PT1/4	PT3/8	8	10	29	29
LF-1034	PT3/8	PT1/2	10	13	34	34

RoHS相当品


R

R

R

## 内・外エルボ

C3771BD

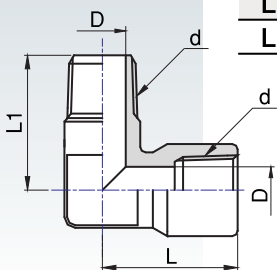


品番	取付ネジ		寸法 (mm)	
	d	$\phi D$	L1	L
LK-1011	PT1/8	4	19	22
LK-1022	PT1/4	8	24	25
LK-1033	PT3/8	10	28	29
LK-1044	PT1/2	13	32	34
LK-1066	PT3/4	19	47	48

R

## 異径内・外エルボ

C3771BD

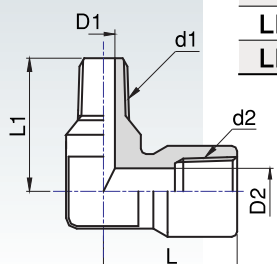

品番	取付ネジ		寸法 (mm)			
	d1	d2	$\phi D1$	$\phi D2$	L1	L
LK-1012	PT1/8	PT1/4	4	8	21	25
LK-1021	PT1/4	PT1/8	8	4	22	22
LK-1023	PT1/4	PT3/8	8	10	29	29
LK-1032	PT3/8	PT1/4	10	8	25	25
LK-1034	PT3/8	PT1/2	10	13	34	34
LK-1043	PT1/2	PT3/8	13	10	29	29

RoHS相当品

R

R

R

R

R

R