
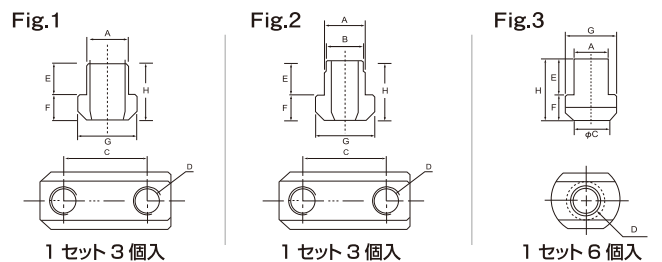


Tナット(ジョーナット) 北川油圧・エアチャック用

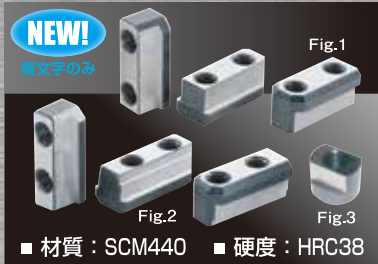

単位: mm

Tナット型式	希望小売価格 (1set3個入/円・税別)	A	B	C	D	E	F	G	H	参考図	ボルト 形式
T05	7,000	10	-	14	M8	9.5	5	14	14.5	Fig.1	CBK204
T-B-05	9,600	10	-	18	M8	10	5.5	14	15.5	Fig.1	CBKB05
T-HJ-5	9,600	10	-	19	M8	12.5	5.5	15	18	Fig.1	-
T06	7,400	12	-	20	M10	11	7.5	17.5	18.5	Fig.1	CBK206
TB06	7,400	12	-	20	M10	15	7	17.5	22	Fig.1	CBK206
T08	8,400	14	-	25	M12	12	8.5	20.5	20.5	Fig.1	CBK208
TB08	8,400	14	-	25	M12	16	10	20.5	26	Fig.1	CBKH08
T10	8,700	16	-	30	M12	13	8.5	22.5	21.5	Fig.1	CBK208
TB10	8,700	16	-	30	M12	16	10	22.5	26	Fig.1	CBKH08
T12	12,000	21	-	30	M16	16.5	11.5	28	28	Fig.1	CBK212
TB12	12,000	18	-	30	M14	20	13.5	26.5	33.5	Fig.1	CBKH12
T-HJ-12	16,000	18	-	38	M14	20	13.5	26.5	33.5	Fig.1	CBK012
T15	21,000	24	22	43	M20	29	16.5	33.5	45.5	Fig.2	CBKB15
TB15	21,000	25.5	-	26	M20	20.25	19	35	39.25	Fig.3	CBKN15
T-KN15	24,000	25.5	-	43	M20	20.25	19	35	39.25	Fig.1	CBKN15
T-HJ-18*	32,000	25	-	60	M20	35	19	37.5	54	Fig.1	CBKJ18
T21	25,000	25	-	27	M20	26	19	37.5	45	Fig.3	CBKN21
T-HJ-24	40,000	25	-	80	M20	35	19	40	54	Fig.1	CBKJ24

*受注生産品です。

北川Tナット兼用表

Tナット型式	共用チャック型式																			
	AS型 AT型 (2爪)	B型 (B-A)	BB型 (BB-A)	BL型 BLT型 (2爪)	BS型 (BS-A)	BT型 (2爪)	HJ型	HJA型	HO型	HOB型	HOBT型 (2爪)	HOH型	HOS型	HW型 (2爪)	ML型 MLT型 MLV型	N型 (N-A)	NL型 NLT型 (2爪)	NRC型	NT型 (2爪)	RC型
T05		204 205				204 205														
T-B-05		05				05			5	5										
T-HJ-5							5									05			05	
T06		206	06 206	206	306	206						206		08						
TB06	06	06				06	6	5-6	6	6	6	06K	6	06	06	06	06	06	06	06
T08		208	08 208	208	308	208						208								
TB08	08	08				08	8	6-8	8	8	8	08K	8	08	08	08	08	08	08	08
T10		210	210	210	310	210														
TB10	10	10				10	10	6-10	10	10	10	10K	10	10 12		10	10	10	10	10
T12		212		212		212														
TB12		12				12		8-12	12A	12	12	12K	12			12	12		12	
T-HJ-12							12		12					15						
T15		15 18				15			15	15	15	15K	15							
TB15		215														15 18				
T-KN15		215														15 18				
T-HJ-18							18 21	11-18 11-21		21 24										
T21		21 24														21 24				
T-HJ-24							24	11-24												

△注意 Tナットの出荷単位: 1セット3個入(チャックの爪数に応じた数量販売はしていません)

生爪