


径違いTの形状・寸法

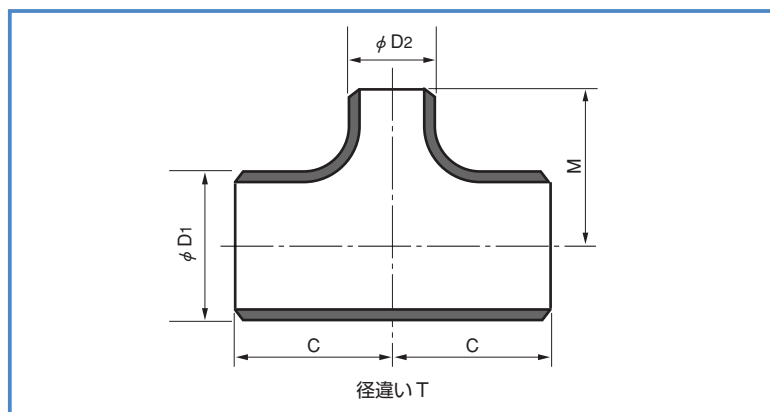

単位：mm

径の呼び		外径		中心から端面までの距離		径の呼び		外径		中心から端面までの距離	
A	B	φD ₁	φD ₂	C	M	A	B	φD ₁	φD ₂	C	M
20 × 15	¾ × ½	27.2	21.7	28.6	28.6	200 × 150	8 × 6	216.3	165.2	177.8	168.3
25 × 20	1 × ¾	34.0	27.2	38.1	38.1	125	5		139.8		161.9
15	½		21.7		38.1	100	4		114.3		155.6
32 × 25	1 ¼ × 1	42.7	34.0	47.6	47.6	90	3 ½		101.6		152.4
20	¾		27.2		47.6	250 × 200	10 × 8	267.4	216.3	215.9	203.2
15	½		21.7		47.6	150	6		165.2		193.7
40 × 32	1 ½ × 1 ¼	48.6	42.7	57.2	57.2	125	5		139.8		190.5
25	1		34.0		57.2	100	4		114.3		184.2
20	¾		27.2		57.2	300 × 250	12 × 10	318.5	267.4	254.0	241.3
15	½		21.7		57.2	200	8		216.3		228.6
50 × 40	2 × 1 ½	60.5	48.6	63.5	60.3	150	6		165.2		219.1
32	1 ¼		42.7		57.2	125	5		139.8		215.9
25	1		34.0		50.8	350 × 300	14 × 12	355.6	318.5	279.4	269.9
20	¾		27.2		44.5	250	10		267.4		257.2
65 × 50	2 ½ × 2	76.3	60.5	76.2	69.9	200	8		216.3		247.7
40	1 ½		48.6		66.7	150	6		165.2		238.1
32	1 ¼		42.7		63.5	400 × 350	16 × 14	406.4	355.6	304.8	304.8
25	1		34.0		57.2	300	12		318.5		295.3
80 × 65	3 × 2 ½	89.1	76.3	85.7	82.6	250	10		267.4		282.6
50	2		60.5		76.2	200	8		216.3		273.1
40	1 ½		48.6		73.0	150	6		165.2		263.5
32	1 ¼		42.7		69.9	450 × 400	18 × 16	457.2	406.4	342.9	330.2
90 × 80	3 ½ × 3	101.6	89.1	95.3	92.1	350	14		355.6		330.2
65	2 ½		76.3		88.9	300	12		318.5		320.7
50	2		60.5		82.6	250	10		267.4		308.0
40	1 ½		48.6		79.4	500 × 450	20 × 18	508.0	457.2	381.0	368.3
100 × 90	4 × 3 ½	114.3	101.6	104.8	101.6	400	16		406.4		355.6
80	3		89.1		98.4	350	14		355.6		355.6
65	2 ½		76.3		95.3	300	12		318.5		346.1
50	2		60.5		88.9	250	10		267.4		333.4
40	1 ½		48.6		85.7	200	8		216.3		323.9
125 × 100	5 × 4	139.8	114.3	123.8	117.5	550 × 500	22 × 20	558.8	508.0	419.1	406.4
90	3 ½		101.6		114.3	450	18		457.2		393.7
80	3		89.1		111.1	400	16		406.4		381.0
65	2 ½		76.3		108.0	600 × 550	24 × 22	609.6	558.8	431.8	431.8
50	2		60.5		104.8	500	20		508.0		431.8
150 × 125	6 × 5	165.2	139.8	142.9	136.5	450	18		457.2		419.1
100	4		114.3		130.2						
90	3 ½		101.6		127.0						
80	3		89.1		123.8						
65	2 ½		76.3		120.7						