


## Parallel clamps and area pressure clamps

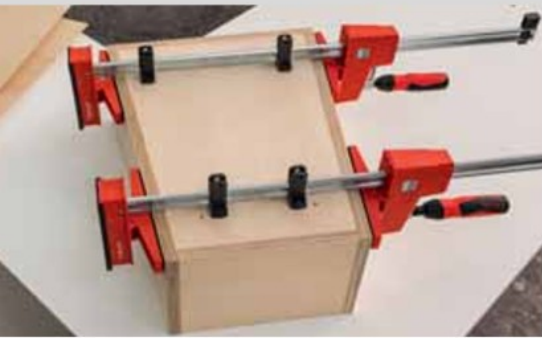

- Adapter with tilting clamping jaws with a tilt range of  $-15^\circ$  to  $+15^\circ$
- Clamping on sloping and parallel surfaces
- On carded hang pack



### Tilting K Body clamp adapter KR-AS (2 pcs./bag)

N <sup>o</sup>	Suitable for					V3
		mm	mm	kg	qty.	
KR-AS	KRE / KREV / KR / KRV	170	25	0.18	12	



[YouTube ▶](#)



- Connect any two K Body parallel clamps to increase the clamping capacity. The connector is made of robust aluminum.
- On carded hang pack



### K Body parallel clamp extender KBX

N <sup>o</sup>	Suitable for			V3
		kg	qty.	
KBX20	KRE / KREV / KR / KRV	0.75	12	

[YouTube ▶](#)

- Especially for DIY applications and domestic appliances
- Special accessory for angle clamps WS 3/WS 6, screw clamp S 10 and K Body REVO parallel clamps KRE/ KREV and KR/KRV to hold them to a work surface edge



### Table clamp

N <sup>o</sup>	∅	<a>	<b>			V3
		mm	mm	mm	kg	
TK6	8	60	22	0.10	50	
RB269	8	60	28	0.19	25	
LM10/5R8	8	100	50	0.22	50	
LM15/5R8	8	150	50	0.25	50	

[YouTube ▶](#)