


45° エルボ (ロング)

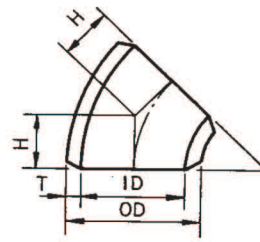

45° エルボ (ショート)

単位: mm

概略重量 (kg)																				径の呼び	
90° エルボ (ロング)					90° エルボ (ショート)					45° エルボ (ロング)					45° エルボ (ショート)						
Sch5S	Sch10S	Sch20S	Sch40	Sch80	Sch5S	Sch10S	Sch20S	Sch40	Sch80	Sch5S	Sch10S	Sch20S	Sch40	Sch80	Sch5S	Sch10S	Sch20S	Sch40	Sch80	A	B
0.049	0.061	0.072	0.079	0.099	-	-	-	-	-	0.025	0.031	0.036	0.039	0.050	-	-	-	-	-	15	1/2
0.063	0.079	0.092	0.105	0.135	-	-	-	-	-	0.031	0.039	0.046	0.053	0.068	-	-	-	-	-	20	3/4
0.080	0.130	0.139	0.155	0.198	0.053	0.087	0.092	0.103	0.132	0.040	0.065	0.069	0.078	0.099	-	-	-	-	-	25	1
0.126	0.208	0.222	0.262	0.345	0.084	0.139	0.148	0.175	0.230	0.063	0.104	0.111	0.131	0.173	0.042	0.070	0.074	0.088	0.115	32	1 1/4
0.173	0.287	0.306	0.372	0.497	0.116	0.191	0.204	0.248	0.331	0.087	0.144	0.153	0.186	0.248	0.058	0.096	0.102	0.124	0.165	40	1 1/2
0.290	0.482	0.595	0.658	0.902	0.193	0.321	0.397	0.439	0.601	0.145	0.241	0.297	0.329	0.451	0.097	0.161	0.198	0.219	0.301	50	2
0.581	0.820	0.950	1.38	1.81	0.387	0.546	0.633	0.919	1.21	0.291	0.410	0.475	0.689	0.905	0.194	0.273	0.317	0.459	0.603	65	2 1/2
0.817	1.16	1.52	2.06	2.77	0.545	0.770	1.02	1.37	1.85	0.409	0.578	0.761	1.03	1.39	0.272	0.385	0.508	0.686	0.924	80	3
1.09	1.54	2.04	2.85	3.95	0.727	1.03	1.36	1.90	2.63	0.545	0.772	1.02	1.43	1.98	0.363	0.515	0.679	0.951	1.32	90	3 1/2
1.41	1.99	2.63	3.88	5.42	0.937	1.33	1.75	2.58	3.61	0.703	0.996	1.32	1.94	2.71	0.468	0.664	0.877	1.29	1.81	100	4
2.86	3.46	5.02	6.55	9.23	1.91	2.30	3.35	4.37	6.15	1.43	1.73	2.51	3.28	4.61	0.953	1.15	1.67	2.18	3.08	125	5
4.07	4.92	7.17	10.0	15.2	2.71	3.28	4.78	6.69	10.1	2.03	2.46	3.58	5.02	7.59	1.36	1.64	2.39	3.35	5.06	150	6
7.13	10.1	16.3	20.4	30.8	4.75	6.75	10.8	13.6	20.6	3.57	5.06	8.13	10.2	15.4	2.38	3.38	5.42	6.78	10.3	200	8
13.4	15.7	25.3	35.8	56.8	8.92	10.5	16.9	23.9	37.9	6.69	7.85	12.6	17.9	28.4	4.46	5.24	8.43	11.9	18.9	250	10
22.5	25.3	36.3	56.8	93.7	15.0	16.9	24.2	37.9	62.5	11.3	12.6	18.1	28.4	46.9	7.50	8.43	12.1	18.9	31.2	300	12

◎ 概略重量は基準寸法による計算値であり、ステンレス鋼(SUS304)の比重 7.93g/cm³ を使用しています。