

## Plug SLS205-L...


In-line, Ø 2 mm with spring-loaded MULTILAM for self-assembly of test leads.

**Solder connection.**

SLS205-L



SLS205-L/N

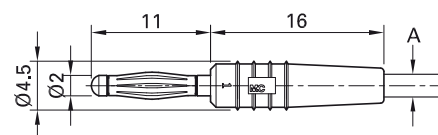

Order No.	Type	Rated voltage/current	Cable (A)		*Standard colors
22.2618-*	SLS205-L	30 VAC / 10 A 60 VDC / 10 A	max. Ø 2.1 mm 0.5 mm <sup>2</sup>	Au	21 22 23 24 25 26 27 28 29
22.2619-*	SLS205-L/N	30 VAC / 10 A 60 VDC / 10 A	max. Ø 2.1 mm 0.5 mm <sup>2</sup>	Ni	21 22 23 24 25 29

### Component parts

22.2010-*	KT2-S	Insulator
22.1009	LS205-L	Plug for SLS205-L
22.5029	LS205-L/N	Plug for SLS205-L/N



Optional colors 26 27 28

Further information, page 6



**Assembly instructions MA136**

[www.staubli.com/electrical](http://www.staubli.com/electrical)