



### エルボ【SP-L】・径違いエルボ【SP-RL】

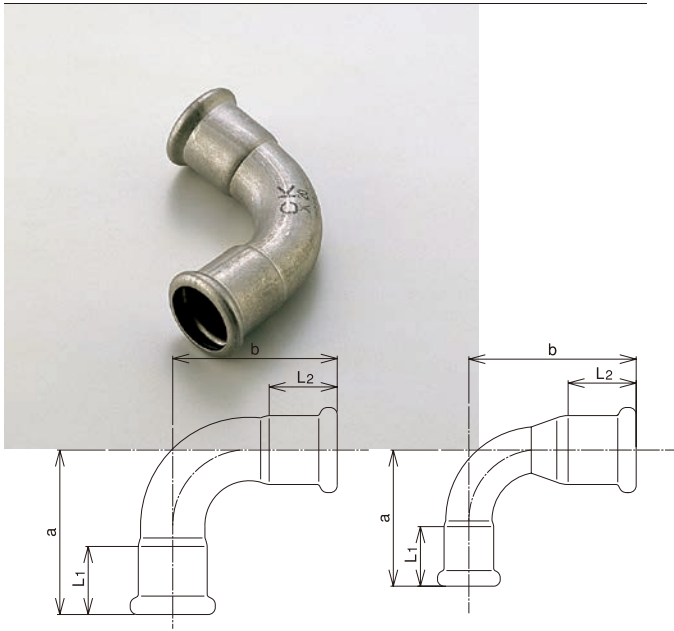

[単位: mm]

呼び方【Su】	a	b	L <sub>1</sub>	L <sub>2</sub>
13	48	48	21	21
20	58	58	24	24
20×13	48	55	21	24
25	66	66	24	24
30	91	91	39	39
40	110	110	47	47
50	122	122	52	52
60	150	150	64	64


### コンパクトエルボ【SP-CL】

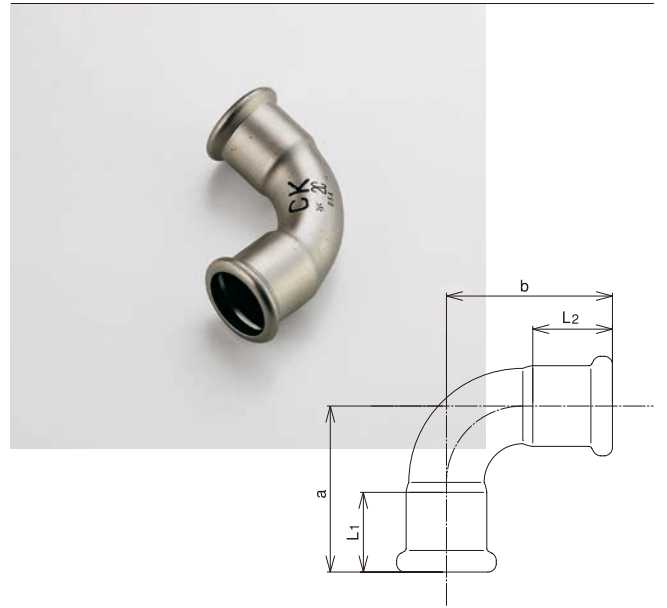

[単位: mm]

呼び方【Su】	a	b	L <sub>1</sub>	L <sub>2</sub>
13	41	41	21	21
20	50	50	24	24
25	54	54	24	24


### 45°エルボ【SP-45L】・径違い45°エルボ【SP-45RL】

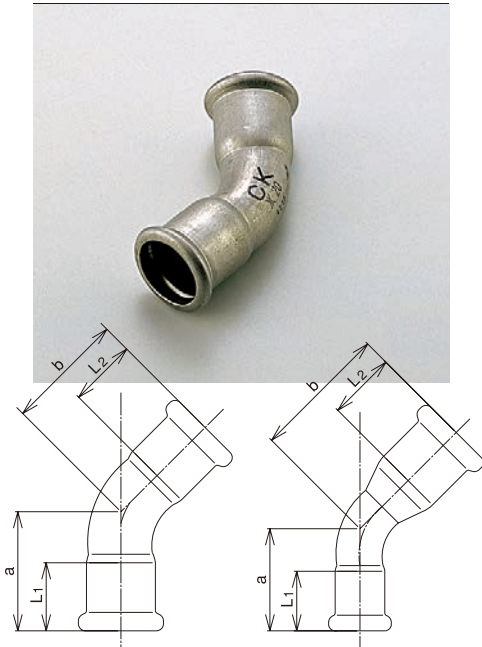

[単位: mm]

呼び方【Su】	a	b	L <sub>1</sub>	L <sub>2</sub>
13	36	36	21	21
20	42	42	24	24
20×13	36	48	21	24
25	46	46	24	24
30	66	66	39	39
40	78	78	47	47
50	87	87	52	52
60	109	109	64	64


### 片ソケットエルボ【SP-SL】

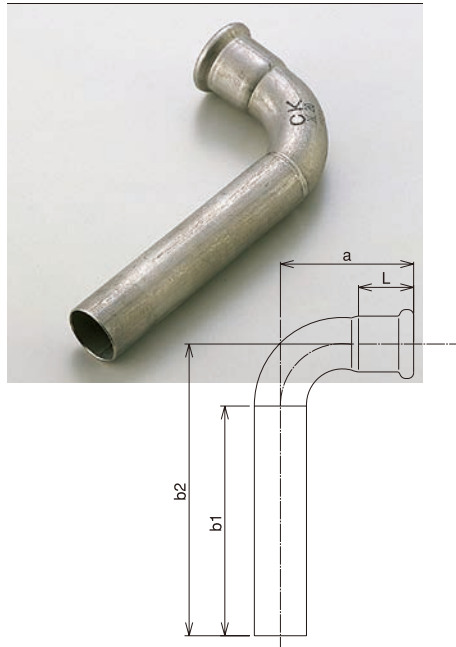

[単位: mm]

呼び方【Su】	a	L	b <sub>1</sub>	b <sub>2</sub>
13	48	21	100	120
20	58	24	100	127
25	66	24	100	135
30	91	39	200	241
40	110	47	200	252
50	122	52	200	259
60	150	64	200	273

### 45°片ソケットエルボ【SP-45SL】

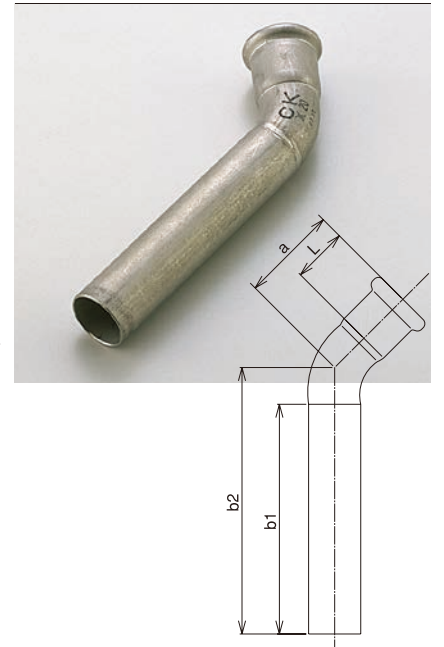

[単位: mm]

呼び方【Su】	a	L	b <sub>1</sub>	b <sub>2</sub>
13	36	21	100	113
20	42	24	100	116
25	46	24	100	120
30	66	39	200	216
40	78	47	200	220
50	87	52	200	224
60	109	64	200	232