


カラビナハーケンC型



SUS 304・鉄 低炭素鋼

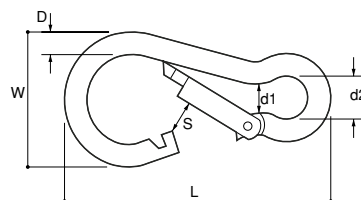


品番	材質	D (mm)	L (mm)	W (mm)	S (mm)	d1 (mm)	d2 (mm)	Weight (g)	試験強度 (kg)	価格
KH- 6CS	SUS304	6	60	31	8	6	9	28	350	¥2,330
KH- 8CS	SUS304	8	80	40	9	8	10	66	750	¥2,640
KH-10CS	SUS304	10	110	55	13	10	15	143	1,500	¥5,350
KH-12CS	SUS304	12	140	70	19	19	20	267	2,000	¥7,900
KH- 6C	鉄	6	60	31	8	6	9	28	350	¥1,240
KH- 8C	鉄	8	80	40	9	8	10	66	750	¥1,320
KH-10C	鉄	10	110	55	13	10	15	143	1,500	¥1,750
KH-12C	鉄	12	140	70	19	19	20	267	2,000	¥2,600

※鉄はニッケルクローム仕上げ

カラビナハーケンCR型



SUS 304・鉄 低炭素鋼

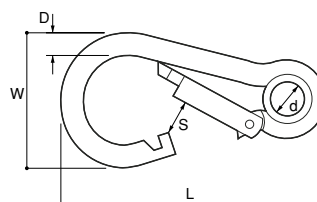

品番	材質	D (mm)	L (mm)	W (mm)	S (mm)	d1 (mm)	Weight (g)	試験強度 (kg)	価格
KH- 6CRS	SUS304	6	60	31	8	9	29.0	350	¥2,520
KH- 8CRS	SUS304	8	80	40	9	10	66.5	750	¥2,880
KH-10CRS	SUS304	10	110	55	13	15	146.0	1,500	¥5,550
KH-12CRS	SUS304	12	140	70	19	20	270.0	2,000	¥8,450
KH- 6CR	鉄	6	60	31	8	9	29.0	250	¥1,260
KH- 8CR	鉄	8	80	40	9	10	66.5	650	¥1,430
KH-10CR	鉄	10	110	55	13	15	146.0	1,500	¥1,920
KH-12CR	鉄	12	140	70	19	20	270.0	2,000	¥3,000

※鉄はニッケルクローム仕上げ