


## カラビナハーケンB型

123


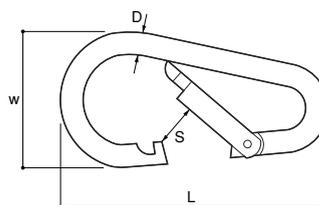


品番	材質	D (mm)	L (mm)	W (mm)	S (mm)	Weight (g)	試験強度 (kg)	価格
KH- 6BS	SUS304	6	60	31	8	27.5	350	¥2,330
KH- 8BS	SUS304	8	80	40	9	65.0	750	¥2,640
KH-10BS	SUS304	10	110	55	15	142.0	1,500	¥5,350
KH-12BS	SUS304	12	140	70	20	266.0	2,000	¥7,900
KH- 6B	鉄	6	60	31	8	27.5	250	¥1,240
KH- 8B	鉄	8	80	40	9	65.0	650	¥1,320
KH-10B	鉄	10	110	55	15	142.0	1,500	¥1,750
KH-12B	鉄	12	140	70	20	266.0	2,000	¥2,600

※鉄はニッケルクローム仕上げ

## ナスカン

123

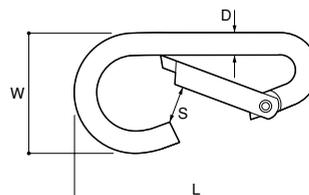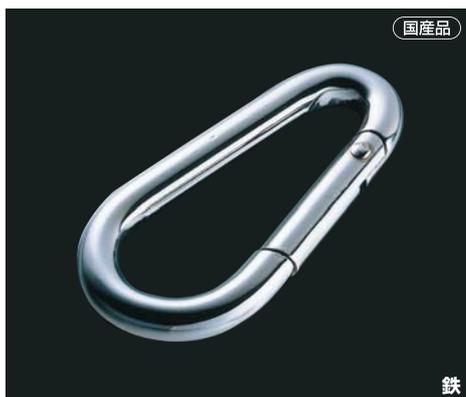

品番	材質	D (mm)	L (mm)	W (mm)	S (mm)	Weight (g)	価格
KNO8	鉄	8	77	38	9	60	¥1,100

※ニッケルメッキ仕上げ