


FITTING

UE UNION ELBOW

ユニオンエルボ

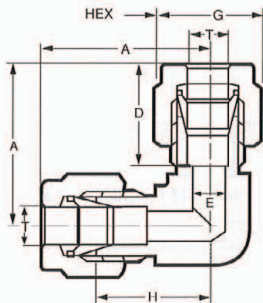

(METRIC)

(Unit:mm)

TUBE O.D. T	PART. No.	A	D	E	G	H
2	UE- 2-0	19.5	9.5	1.3	8	15
3	UE- 3-0	25	15	2.5	12	18
4	UE- 4-0	28.3	15.3	3.5	14	21
6	UE- 6-0	28.4	15.4	5	14	21
8	UE- 8-0	28.8	16.8	6	15.87	21
10	UE-10-0	31.7	18.7	8	19	23
12	UE-12-0	34.8	22.8	10	23	24
14	UE-14-0	39.5	24.5	12	26	29
15	UE-15-0	39	24	12	26	29
16	UE-16-0	39.5	24.5	12	26	29
18	UE-18-0	41	25	15	30	30
20	UE-20-0	43	25	17	32	32
22	UE-22-0	43.2	25.2	18	35	32
25	UE-25-0	48.5	33.5	22	38	34

(INCHES)

※管外径5φも製作しております。

1/16" : 1.6	UE-005-0	19	9	1.3	8	15
1/8" : 3.18	UE- 01-0	25	15	2.5	12	18
1/4" : 6.35	UE- 02-0	28.4	15.4	5	14	21
5/16" : 7.94	UE-025-0	28.8	16.8	6	15.87	21
3/8" : 9.53	UE- 03-0	31.3	17.8	7	17.46	23
1/2" : 12.7	UE- 04-0	34.8	22.8	10	23	24
5/8" : 15.87	UE- 05-0	39	24	12	26	29
3/4" : 19.05	UE- 06-0	41	25	16	30	30
7/8" : 22.23	UE- 07-0	43.2	25.2	18	35	32
1" : 25.4	UE- 08-0	48	33	22	38	34

(SCHEDULE)


※管外径3/16"も製作しております。

1/8 B : 10.5	UE-10.5-0	32.2	19.2	8	19	23
1/4 B : 13.8	UE-13.8-0	39	24	12	26	29
3/8 B : 17.3	UE-17.3-0	41	25	15	30	30
1/2 B : 21.7	UE-21.7-0	43.2	25.2	18	35	32

A.D:FINGER TIGHT-±0.5mm (about)

UT UNION TEE

ユニオンチーズ

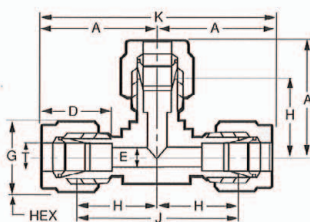

(METRIC)

(Unit:mm)

TUBE O.D. T	PART. No.	A	D	E	G	H	J	K
2	UT- 2-0	19.5	9.5	1.3	8	30	15	39
3	UT- 3-0	25	15	2.5	12	18	36	50
4	UT- 4-0	28.3	15.3	3.5	14	21	42	56.6
6	UT- 6-0	28.4	15.4	5	14	21	42	56.8
8	UT- 8-0	29.4	16.8	6	15.87	22	44	59.6
10	UT-10-0	31.7	18.7	8	19	23	46	63.4
12	UT-12-0	38.3	22.8	10	23	27.5	55	76.6
14	UT-14-0	39.5	24.5	12	26	29	58	79
15	UT-15-0	39	24	12	26	29	58	78
16	UT-16-0	39.5	24.5	12	26	29	58	79
18	UT-18-0	41	25	15	30	30	60	82
20	UT-20-0	43	25	17	32	32	64	86
22	UT-22-0	43.2	25.2	18	35	32	64	86.4
25	UT-25-0	48.5	33.5	22	38	34	68	97

(INCHES)

※管外径5φも製作しております。

1.6	UT-005-0	19	9	1.3	8	30	15	38
1/8" : 3.18	UT- 01-0	25	15	2.5	12	18	36	50
1/4" : 6.35	UT- 02-0	28.4	15.4	5	14	21	42	56.8
5/16" : 7.94	UT-025-0	29.8	16.8	6	15.87	22	44	59.6
3/8" : 9.53	UT- 03-0	31.3	17.8	7	17.46	23	46	62.6
1/2" : 12.7	UT- 04-0	38.3	22.8	10	23	27.5	55	76.3
5/8" : 15.87	UT- 05-0	39	24	12	26	29	58	78
3/4" : 19.05	UT- 06-0	41	24	16	30	30	60	82
7/8" : 22.23	UT- 07-0	43.2	25.2	18	35	32	64	86.4
1" : 25.4	UT- 08-0	48	33	22	38	34	68	96

(SCHEDULE)

※管外径3/16"も製作しております。

1/8 B : 10.5	UT-10.5-0	32.2	19.2	8	19	23	46	64.4
1/4 B : 13.8	UT-13.8-0	39	24	12	26	29	58	78
3/8 B : 17.3	UT-17.3-0	41	25	15	30	30	60	82
1/2 B : 21.7	UT-21.7-0	43.2	25.2	18	35	32	64	86.4