



MINIATURE VALVES

VSP

■高圧用 (260kgf/cm²・26MPa)

NEEDLE STOP VALVE

ネジ込み型

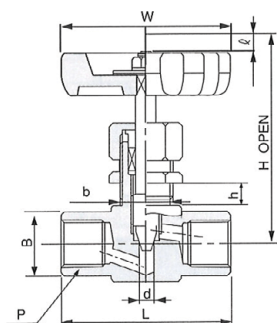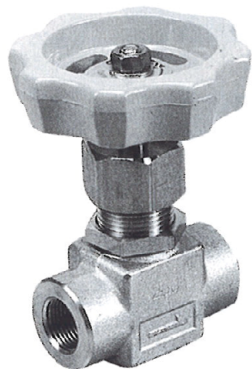


■仕様

SIZE	MAX Cv値	TEMPERATURE
1/8 B	0.36	-20°C
1/4 B	0.48	
3/8 B	0.66	150°C
1/2 B	0.82	
3/4 B	1.82	


■材質

NAME	MATELIAL
BODY	SUS 316
STEM	SUS 316 +STELLITE
PACKING	PTFE
HANDLE	ADC 12

■圧力-温度基準

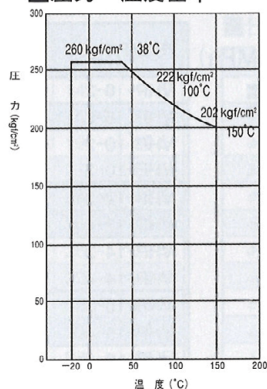

■Cv値曲線

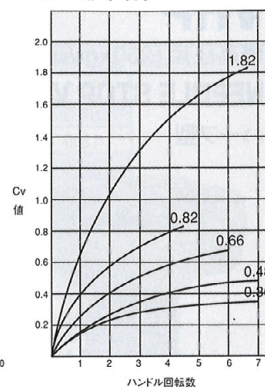

■寸法表

(Unit:mm)



PART. No.	SIZE	P PT or NPT	d	L	H	ℓ	h	W	B	b	重量 (g)
VSP-101F	1/8 B	1/8	5	50	73	7	7	58	22	18.5	300
VSP-202F	1/4 B	1/4	5	50	73	7	7	58	22	18.5	290
VSP-303F	3/8 B	3/8	6	56	80	6	7	68	28	22.5	480
VSP-404F	1/2 B	1/2	8	62	86	6.5	7	68	32	22.5	575
VSP-606F	3/4 B	3/4	10	70	107	10	7	78	38	25.5	900

VWP

■高圧用 (260kgf/cm²・26MPa)

NEEDLE STOP VALVE

ソケットウェルド型

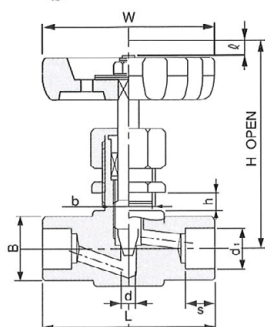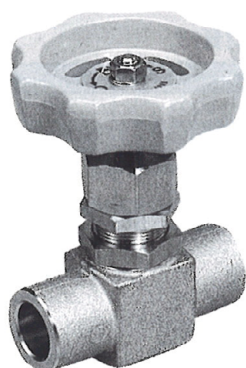


■仕様

SIZE	MAX Cv値	TEMPERATURE
1/8 B	0.36	-20°C
1/4 B	0.48	
3/8 B	0.66	150°C
1/2 B	0.82	
3/4 B	1.82	


■材質

NAME	MATELIAL
BODY	SUS 316
STEM	SUS 316 +STELLITE
PACKING	PTFE
HANDLE	ADC 12

■圧力-温度基準

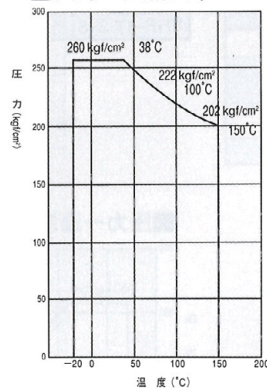

■Cv値曲線

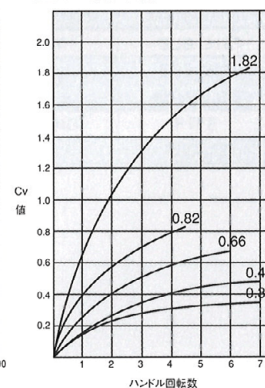

■寸法表

(Unit:mm)

PART. No.	SIZE	P PT or NPT	d ₁ S·W	L	S	H	ℓ	h	W	B	b	重量 (g)
VWP-101S	1/8 B	11.0	5	58	10	73	7	7	58	22	18.5	320
VWP-202S	1/4 B	14.3	5	58	10	73	7	7	58	22	18.5	310
VWP-303S	3/8 B	17.8	6	63	13	80	6	7	68	28	22.5	505
VWP-404S	1/2 B	22.2	8	73	13	86	6.5	7	68	32	22.5	655
VWP-606S	3/4 B	27.7	10	70	16	107	10	7	78	38	25.5	900