
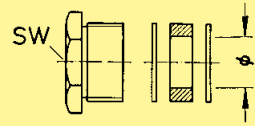

 

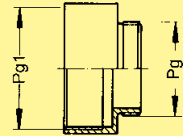

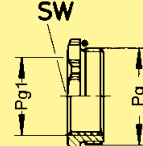

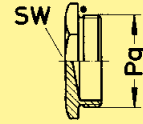
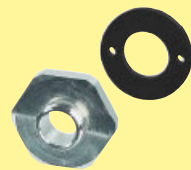
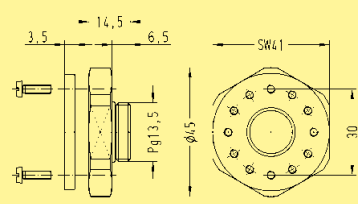


# ケーブルエントリープロテクション (Pg ネジ)



名称	部品番号	Pg	図	寸法 mm																				
ケーブルグランド (IP 65) サーマプラスチック 単層シール付 	グレー 09 00 000 5164	11		<table border="1"> <thead> <tr> <th>SW</th> <th>ケーブル ̢ D</th> </tr> </thead> <tbody> <tr> <td>19</td> <td>10 ... 12</td> </tr> <tr> <td>19</td> <td>10 ... 12</td> </tr> </tbody> </table>	SW	ケーブル ̢ D	19	10 ... 12	19	10 ... 12														
	SW	ケーブル ̢ D																						
19	10 ... 12																							
19	10 ... 12																							
黒色 09 00 000 5185	11																							
ケーブルグランド (IP 65) 金属製 多層シール付 	09 00 000 5013	11		<table border="1"> <thead> <tr> <th>SW</th> <th>ケーブル ̢ D</th> </tr> </thead> <tbody> <tr> <td>18</td> <td>6.5 ... 12</td> </tr> <tr> <td>20</td> <td>6.5 ... 13.5</td> </tr> <tr> <td>22</td> <td>6.5 ... 16</td> </tr> <tr> <td>28</td> <td>9 ... 20</td> </tr> <tr> <td>37</td> <td>17 ... 28</td> </tr> <tr> <td>47</td> <td>23 ... 34</td> </tr> <tr> <td>54</td> <td>29 ... 40</td> </tr> </tbody> </table>	SW	ケーブル ̢ D	18	6.5 ... 12	20	6.5 ... 13.5	22	6.5 ... 16	28	9 ... 20	37	17 ... 28	47	23 ... 34	54	29 ... 40				
	SW	ケーブル ̢ D																						
	18	6.5 ... 12																						
	20	6.5 ... 13.5																						
	22	6.5 ... 16																						
	28	9 ... 20																						
	37	17 ... 28																						
	47	23 ... 34																						
54	29 ... 40																							
09 00 000 5014	13.5																							
09 00 000 5015	16																							
09 00 000 5016	21																							
09 00 000 5017	29																							
09 00 000 5018	36																							
09 00 000 5019	42																							
Pg ネジ用拡大アダプター 金属製 	09 00 000 5050	11		<table border="1"> <thead> <tr> <th>Pg1</th> </tr> </thead> <tbody> <tr> <td>13.5</td> </tr> <tr> <td>16</td> </tr> <tr> <td>21</td> </tr> <tr> <td>29</td> </tr> <tr> <td>36</td> </tr> <tr> <td>42</td> </tr> <tr> <td>48</td> </tr> </tbody> </table>	Pg1	13.5	16	21	29	36	42	48												
	Pg1																							
	13.5																							
	16																							
	21																							
	29																							
	36																							
	42																							
48																								
09 00 000 5051	13.5																							
09 00 000 5052	16																							
09 00 000 5053	21																							
09 00 000 5054	29																							
09 00 000 5055	36																							
09 00 000 5056	42																							
縮小アダプター Pg ケーブルエントリー用 金属製 	09 00 000 5060	11		<table border="1"> <thead> <tr> <th>SW</th> <th>Pg1</th> </tr> </thead> <tbody> <tr> <td>20</td> <td>7</td> </tr> <tr> <td>20</td> <td>9</td> </tr> <tr> <td>22</td> <td>9</td> </tr> <tr> <td>22</td> <td>11</td> </tr> <tr> <td>24</td> <td>13.5</td> </tr> <tr> <td>30</td> <td>13.5</td> </tr> <tr> <td>30</td> <td>16</td> </tr> <tr> <td>40</td> <td>16</td> </tr> <tr> <td>40</td> <td>21</td> </tr> </tbody> </table>	SW	Pg1	20	7	20	9	22	9	22	11	24	13.5	30	13.5	30	16	40	16	40	21
	SW	Pg1																						
	20	7																						
	20	9																						
	22	9																						
	22	11																						
	24	13.5																						
	30	13.5																						
	30	16																						
40	16																							
40	21																							
09 00 000 5061	11																							
09 00 000 5062	13.5																							
09 00 000 5063	13.5																							
09 00 000 5064	16																							
09 00 000 5065	21																							
09 00 000 5066	21																							
09 00 000 5067	29																							
09 00 000 5068	29																							
メクラ栓 Pg ケーブルエントリー用 金属製 	09 00 000 5070	11		<table border="1"> <thead> <tr> <th>SW</th> </tr> </thead> <tbody> <tr> <td>20</td> </tr> <tr> <td>22</td> </tr> <tr> <td>24</td> </tr> <tr> <td>30</td> </tr> <tr> <td>40</td> </tr> <tr> <td>50</td> </tr> </tbody> </table>	SW	20	22	24	30	40	50													
	SW																							
	20																							
	22																							
	24																							
	30																							
	40																							
50																								
09 00 000 5071	13.5																							
09 00 000 5072	16																							
09 00 000 5073	21																							
09 00 000 5074	29																							
09 00 000 5075	36																							
Han® 3 A アダプター モーター接続用 	09 20 000 9962	13.5		ページ 40.07 参照																				
	09 20 000 9962																							

太字はドイツでの標準在庫品