

CL-7000



Lever

Push

CL-9000 (with Shockless Stand)



Push

A long seller with a wide range of torque and reliable operability

- A wide range of torque enables accurate fastening.
- Easy-to-hold small diameter grip reduces workload.
- Supports high torque screw fastening up to 5N·m (CL-9000).

RELATED PRODUCTS

Power Supply with Screw Counter

CLT-70STC3

With screw counter that prevents screw skipping by displaying remaining No. of screws.

See [P.41](#)



Separate Counter



CLOP-SC1

The counter can be used by connecting it to existing HIOS power supply.

See [P.41](#)



Output Torque Guide (HI Input) ❖

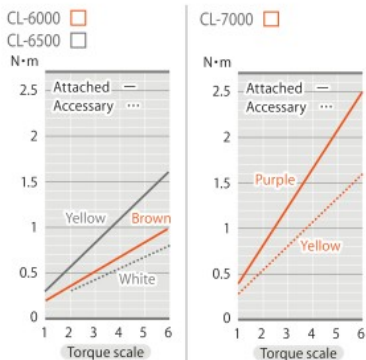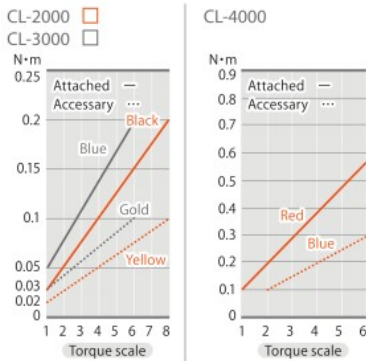

* The colors in the chart indicate the spring colors. CL-9000: For torque adjustment, refer to the torque scale sticker affixed to the main body.

❖ For some models, two torque adjustment springs, for HI torque (installed) and for LOW torque (accessory), are included. Please use a suitable one for your operation.

APPLICABLE DRIVERS Variations

Suction

CLQ



See [P.51](#)

Anti-electrostatic

CL-ESD



For Clean Room/Anti-electrostatic

CLQ-CR-ESD



See [P.51](#)

Noiseless

CL-NL



ACCESSORIES

Pistol Attachment

PA-65

Can be converted to a pistol type, which is optimal for horizontal fastening.



Applicable models: CL-6000, CL-6500, CL-7000 (including Push-to start type)

Angle Attachment

ANGL-Z (H5) ANGLX-Z (1/4HEX)

By attaching this to the tip, you can work smoothly in a narrow space.



Set the output to 1.2 N·m or smaller attachment.

Applicable models: CL-6000, CL-6500, CL-7000 (Lever start type only)

Grip Attachment for Push-to-start

PS-1 PS-1-ESD (Anti-electrostatic)

This attachment changes start type from Lever to Push.



Applicable model: CL-4000



When attached