



9. ダストキャップ

9.1 DX-※※-DC(半硬質、ワンタッチロック用)タイプ

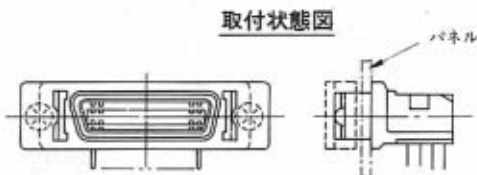

DX-50-DC

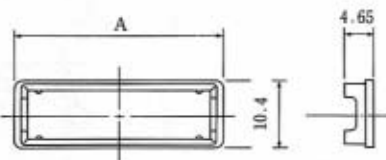

取付状態図

パネル



単位(mm)

HRS No.	極数	製品番号	A	RoHS
CL230-0103-1	20	DX-20-DC	27.35	○
CL230-0045-7	28	DX-28-DC	32.43	○
CL230-0241-5	36	DX-36-DC	37.5	○
CL230-0104-4	50	DX-50-DC	46.4	○
CL230-0078-6	68	DX-68-DC	57.83	○
CL230-0046-0	80	DX-80-DC	65.45	○

9.2 DX-100S-DC1(半硬質、ワンタッチロック用、スクリューロック用)タイプ



  DX-100S-DC1




HRS No.	製品番号	RoHS
CL230-0114-8	DX-100S-DC1	○

取付状態図





パネル

9.3 DX-※※S-DC2(軟質、ワンタッチロック用、スクリューロック用)タイプ

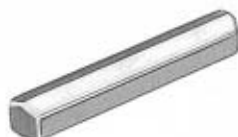

DX-36S-DC2(50)

  

取付状態図



単位(mm)

HRS No.	極数	製品番号	A	RoHS
CL230-0105-7-50	36	DX-36S-DC2(50)	28.07	○
CL230-0264-0-50	50	DX-50S-DC2(50)	36.96	○
CL230-0106-0-50	68	DX-68S-DC2(50)	48.39	○