



エルボ
(PQWK-L)

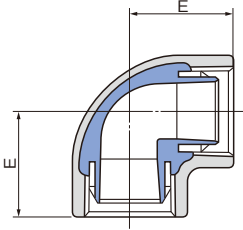

(単位:mm)

呼び	E	ねじ
1/2	27	Rc1/2
3/4	32	Rc3/4
1	38	Rc1
1 1/4	46	Rc1 1/4
1 1/2	48	Rc1 1/2
2	57	Rc2


エルボ(バンド付き)
(PQWK-BL)

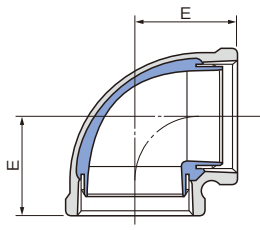

(単位:mm)

呼び	E	ねじ
2 1/2	69	Rc2 1/2
3	78	Rc3
4	97	Rc4
5	113	Rc5
6	132	Rc6


径違いエルボ
(PQWK-RL)

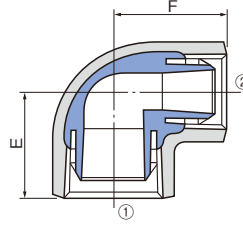

(単位:mm)

呼び	E	F	ねじ①	ねじ②
3/4 x 1/2	29	30	Rc3/4	Rc1/2
1 x 1/2	32	33	Rc1	Rc1/2
1 x 3/4	34	35	Rc1	Rc3/4
1 1/4 x 3/4	38	40	Rc1 1/4	Rc3/4
1 1/4 x 1	40	42	Rc1 1/4	Rc1
1 1/2 x 1	41	45	Rc1 1/2	Rc1
1 1/2 x 1 1/4	45	48	Rc1 1/2	Rc1 1/4
2 x 1 1/4	48	54	Rc2	Rc1 1/4
2 x 1 1/2	52	55	Rc2	Rc1 1/2


径違いエルボ(バンド付き)
(PQWK-BRL)

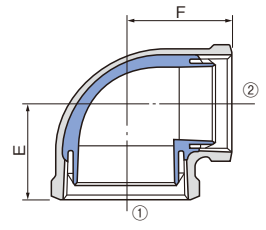

(単位:mm)

呼び径	E	F	ねじ①	ねじ②
1 1/2 x 1/2	35	42	Rc1 1/2	Rc1/2
1 1/2 x 3/4	38	43	Rc1 1/2	Rc3/4
2 x 3/4	41	49	Rc2	Rc3/4
2 x 1	44	51	Rc2	Rc1
2 1/2 x 1 1/2	55	62	Rc2 1/2	Rc1 1/2
2 1/2 x 2	60	65	Rc2 1/2	Rc2
3 x 1 1/2	58	72	Rc3	Rc1 1/2
3 x 2	62	72	Rc3	Rc2
3 x 2 1/2	72	75	Rc3	Rc2 1/2
4 x 2	69	87	Rc4	Rc2
4 x 2 1/2	78	90	Rc4	Rc2 1/2
4 x 3	83	91	Rc4	Rc3


45°エルボ
(PQWKBL45)

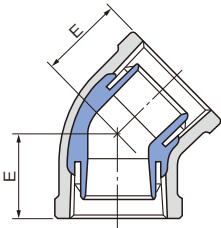

(単位:mm)

呼び	E	ねじ
1/2	21	Rc1/2
3/4	25	Rc3/4
1	29	Rc1
1 1/4	34	Rc1 1/4
1 1/2	37	Rc1 1/2
2	42	Rc2
2 1/2	49	Rc2 1/2
3	54	Rc3
4	65	Rc4


T
(PQWK-T)

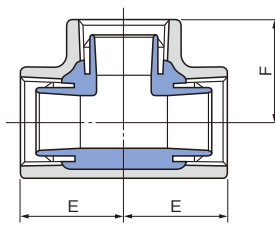

(単位:mm)

呼び	E	F	ねじ
1/2	27	27	Rc1/2
3/4	32	32	Rc3/4
1	38	38	Rc1
1 1/4	46	46	Rc1 1/4
1 1/2	48	48	Rc1 1/2
2	57	57	Rc2



T(バンド付き)
(PQWK-BT)

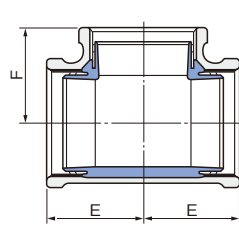

(単位:mm)

呼び	E	F	ねじ
2 1/2	69	69	Rc2 1/2
3	78	78	Rc3
4	97	97	Rc4
5	113	113	Rc5
6	132	132	Rc6

3方径違いT(バンド付き)
(PQWK-BRT)

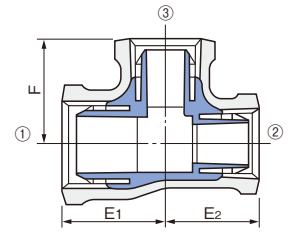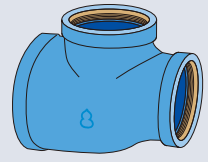

(単位:mm)

呼び	E1	E2	F	ねじ①	ねじ②③
* 3/4 x 1/2 x 1/2	30	27	30	Rc3/4	Rc1/2

*は(社)日本水道協会品質認証センター
認証登録品ではありません。