


* 印は「JIS B 2301 ねじ込み式可鍛鉄製管継手」規格外品です。
○印は受注生産品です。

9 径違いエルボ(バンド付) (WS-BRL)
Elbows, 90°, banded, reducing

(呼び $\frac{3}{4}$ ~5)

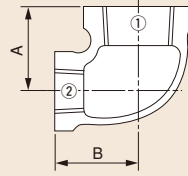


(単位: mm)

呼び径 (A)	呼 び ①×②	中心から端面までの距離	
		A	B
20×15	$\frac{3}{4} \times \frac{1}{2}$	29	30
25×15	$1 \times \frac{1}{2}$	32	33
25×20	$1 \times \frac{3}{4}$	34	35
32×15	$1\frac{1}{4} \times \frac{1}{2}$	34	38
32×20	$1\frac{1}{4} \times \frac{3}{4}$	38	40
32×25	$1\frac{1}{4} \times 1$	40	42
40×15	$1\frac{1}{2} \times \frac{1}{2}$	35	42
40×20	$1\frac{1}{2} \times \frac{3}{4}$	38	43
40×25	$1\frac{1}{2} \times 1$	41	45
40×32	$1\frac{1}{2} \times 1\frac{1}{4}$	45	48
50×15	$2 \times \frac{1}{2}$	38	48
50×20	$2 \times \frac{3}{4}$	41	49
50×25	2×1	44	51
50×32	$2 \times 1\frac{1}{4}$	48	54
50×40	$2 \times 1\frac{1}{2}$	52	55
* 65×20	$2\frac{1}{2} \times \frac{3}{4}$	44	58
65×25	$2\frac{1}{2} \times 1$	48	60


呼び径 (A)	呼 び ①×②	中心から端面までの距離	
		A	B
65×32	$2\frac{1}{2} \times 1\frac{1}{4}$	52	62
65×40	$2\frac{1}{2} \times 1\frac{1}{2}$	55	62
65×50	$2\frac{1}{2} \times 2$	60	65
* 80×15	$3 \times \frac{1}{2}$	44	64
* 80×20	$3 \times \frac{3}{4}$	46	66
* 80×25	3×1	50	68
80×32	$3 \times 1\frac{1}{4}$	55	70
80×40	$3 \times 1\frac{1}{2}$	58	72
80×50	3×2	62	72
80×65	$3 \times 2\frac{1}{2}$	72	75
* 100×40	$4 \times 1\frac{1}{2}$	63	86
100×50	4×2	69	87
100×65	$4 \times 2\frac{1}{2}$	78	90
100×80	4×3	83	91
○ 125×80	5×3	87	107
○ 125×100	5×4	100	111

10 三方径違いT(バンド付) (WS-BRT)
Tees, banded, reducing

(呼び $\frac{3}{4}$ ~2 $\frac{1}{2}$)

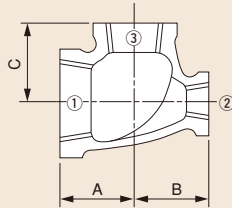

呼び径および呼び順位

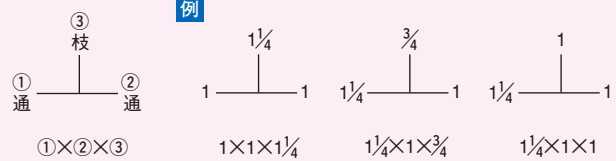

(単位: mm)

呼び径 (A)	呼 び ①×②×③	中心から端面までの距離		
		A	B	C
20×20×25	$\frac{3}{4} \times \frac{3}{4} \times 1$	35	35	34
20×20×32	$\frac{3}{4} \times \frac{3}{4} \times 1\frac{1}{4}$	40	40	38
25×20×15	$1 \times \frac{3}{4} \times \frac{1}{2}$	32	29	33
25×20×20	$1 \times \frac{3}{4} \times \frac{3}{4}$	34	32	35
25×20×25	$1 \times \frac{3}{4} \times 1$	38	35	38
25×25×32	$1 \times 1 \times 1\frac{1}{4}$	42	42	40
25×25×40	$1 \times 1 \times 1\frac{1}{2}$	45	45	42
* 25×25×50	$1 \times 1 \times 2$	51	51	44
* 32×15×20	$1\frac{1}{4} \times \frac{1}{2} \times \frac{3}{4}$	37	30	40
32×20×20	$1\frac{1}{4} \times \frac{3}{4} \times \frac{3}{4}$	37	32	40
32×25×15	$1\frac{1}{4} \times 1 \times \frac{1}{2}$	34	32	38
32×25×20	$1\frac{1}{4} \times 1 \times \frac{3}{4}$	37	34	40
32×25×25	$1\frac{1}{4} \times 1 \times 1$	40	38	42
32×25×32	$1\frac{1}{4} \times 1 \times 1\frac{1}{4}$	46	42	46
* 32×25×40	$1\frac{1}{4} \times 1 \times 1\frac{1}{2}$	48	45	45
32×32×40	$1\frac{1}{4} \times 1\frac{1}{4} \times 1\frac{1}{2}$	48	48	45
32×32×50	$1\frac{1}{4} \times 1\frac{1}{4} \times 2$	52	52	48
* 40×20×20	$1\frac{1}{2} \times \frac{3}{4} \times \frac{3}{4}$	38	32	43
40×25×25	$1\frac{1}{2} \times 1 \times 1$	41	37	45
40×25×32	$1\frac{1}{2} \times 1 \times 1\frac{1}{4}$	45	42	48
40×25×40	$1\frac{1}{2} \times 1 \times 1\frac{1}{2}$	48	45	48
* 40×25×50	$1\frac{1}{2} \times 1 \times 2$	53	50	51
40×32×15	$1\frac{1}{2} \times 1\frac{1}{4} \times \frac{1}{2}$	35	34	42
40×32×20	$1\frac{1}{2} \times 1\frac{1}{4} \times \frac{3}{4}$	38	38	43
40×32×25	$1\frac{1}{2} \times 1\frac{1}{4} \times 1$	41	40	45
40×32×32	$1\frac{1}{2} \times 1\frac{1}{4} \times 1\frac{1}{4}$	45	44	48
40×32×40	$1\frac{1}{2} \times 1\frac{1}{4} \times 1\frac{1}{2}$	48	48	48
* 40×32×50	$1\frac{1}{2} \times 1\frac{1}{4} \times 2$	55	54	52

呼び径 (A)	呼 び ①×②×③	中心から端面までの距離		
		A	B	C
40×40×50	$1\frac{1}{2} \times 1\frac{1}{2} \times 2$	54	54	52
* 40×40×65	$1\frac{1}{2} \times 1\frac{1}{2} \times 2\frac{1}{2}$	62	62	55
50×20×50	$2 \times \frac{3}{4} \times 2$	57	49	57
* 50×25×32	$2 \times 1 \times 1\frac{1}{4}$	48	42	54
* 50×25×40	$2 \times 1 \times 1\frac{1}{2}$	52	45	55
50×25×50	$2 \times 1 \times 2$	57	52	57
* 50×32×25	$2 \times 1\frac{1}{4} \times 1$	45	41	52
50×32×32	$2 \times 1\frac{1}{4} \times 1\frac{1}{4}$	48	46	54
50×32×40	$2 \times 1\frac{1}{4} \times 1\frac{1}{2}$	52	48	55
50×32×50	$2 \times 1\frac{1}{4} \times 2$	57	54	57
* 50×40×15	$2 \times 1\frac{1}{2} \times \frac{1}{2}$	38	35	48
50×40×20	$2 \times 1\frac{1}{2} \times \frac{3}{4}$	41	38	50
50×40×25	$2 \times 1\frac{1}{2} \times 1$	45	42	52
50×40×32	$2 \times 1\frac{1}{2} \times 1\frac{1}{4}$	49	46	54
50×40×40	$2 \times 1\frac{1}{2} \times 1\frac{1}{2}$	52	48	55
50×40×50	$2 \times 1\frac{1}{2} \times 2$	57	55	57
* 50×40×65	$2 \times 1\frac{1}{2} \times 2\frac{1}{2}$	65	62	60
50×50×65	$2 \times 2 \times 2\frac{1}{2}$	65	65	60
50×50×80	$2 \times 2 \times 3$	72	72	62
* 65×40×50	$2\frac{1}{2} \times 1\frac{1}{2} \times 2$	60	55	65
* 65×40×65	$2\frac{1}{2} \times 1\frac{1}{2} \times 2\frac{1}{2}$	69	62	69
* 65×50×25	$2\frac{1}{2} \times 2 \times 1$	48	45	61
* 65×50×32	$2\frac{1}{2} \times 2 \times 1\frac{1}{4}$	52	48	62
* 65×50×40	$2\frac{1}{2} \times 2 \times 1\frac{1}{2}$	55	52	62
* 65×50×50	$2\frac{1}{2} \times 2 \times 2$	60	57	65
* 65×50×65	$2\frac{1}{2} \times 2 \times 2\frac{1}{2}$	69	65	69
65×65×80	$2\frac{1}{2} \times 2\frac{1}{2} \times 3$	75	75	70