


* 印は「JIS B 2301 ねじ込み式可鍛鉄製管継手」規格外品です。
○印は受注生産品です。

11 径違いT (バンド付) (枝径だけ異なるもの) (WS-BRT)
Tees banded, reducing

(呼び $\frac{3}{4}$ ~6)

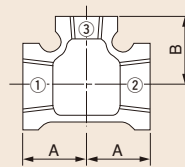


(単位: mm)

呼び径 (A)	呼 び ①×②×③	中心から端面までの距離	
		A	B
20×20×15	$\frac{3}{4} \times \frac{3}{4} \times \frac{1}{2}$	29	30
25×25×15	$1 \times 1 \times \frac{1}{2}$	32	33
25×25×20	$1 \times 1 \times \frac{3}{4}$	34	35
32×32×15	$1\frac{1}{4} \times 1\frac{1}{4} \times \frac{1}{2}$	34	38
32×32×20	$1\frac{1}{4} \times 1\frac{1}{4} \times \frac{3}{4}$	38	40
32×32×25	$1\frac{1}{4} \times 1\frac{1}{4} \times 1$	40	42
40×40×15	$1\frac{1}{2} \times 1\frac{1}{2} \times \frac{1}{2}$	35	42
40×40×20	$1\frac{1}{2} \times 1\frac{1}{2} \times \frac{3}{4}$	38	43
40×40×25	$1\frac{1}{2} \times 1\frac{1}{2} \times 1$	41	45
40×40×32	$1\frac{1}{2} \times 1\frac{1}{2} \times 1\frac{1}{4}$	45	48
50×50×15	$2 \times 2 \times \frac{1}{2}$	38	48
50×50×20	$2 \times 2 \times \frac{3}{4}$	41	49
50×50×25	$2 \times 2 \times 1$	44	51
50×50×32	$2 \times 2 \times 1\frac{1}{4}$	48	54
50×50×40	$2 \times 2 \times 1\frac{1}{2}$	52	55
65×65×15	$2\frac{1}{2} \times 2\frac{1}{2} \times \frac{1}{2}$	41	57
65×65×20	$2\frac{1}{2} \times 2\frac{1}{2} \times \frac{3}{4}$	44	58
65×65×25	$2\frac{1}{2} \times 2\frac{1}{2} \times 1$	48	60
65×65×32	$2\frac{1}{2} \times 2\frac{1}{2} \times 1\frac{1}{4}$	52	62
65×65×40	$2\frac{1}{2} \times 2\frac{1}{2} \times 1\frac{1}{2}$	55	62
65×65×50	$2\frac{1}{2} \times 2\frac{1}{2} \times 2$	60	65
* 80×80×15	$3 \times 3 \times \frac{1}{2}$	43	65
80×80×20	$3 \times 3 \times \frac{3}{4}$	46	66
80×80×25	$3 \times 3 \times 1$	50	68
80×80×32	$3 \times 3 \times 1\frac{1}{4}$	55	70
80×80×40	$3 \times 3 \times 1\frac{1}{2}$	58	72

呼び径 (A)	呼 び ①×②×③	中心から端面までの距離	
		A	B
80×80×50	$3 \times 3 \times 2$	62	72
80×80×65	$3 \times 3 \times 2\frac{1}{2}$	72	75
* 100×100×15	$4 \times 4 \times \frac{1}{2}$	50	79
100×100×20	$4 \times 4 \times \frac{3}{4}$	54	80
100×100×25	$4 \times 4 \times 1$	57	83
100×100×32	$4 \times 4 \times 1\frac{1}{4}$	61	86
100×100×40	$4 \times 4 \times 1\frac{1}{2}$	63	86
100×100×50	$4 \times 4 \times 2$	69	87
100×100×65	$4 \times 4 \times 2\frac{1}{2}$	78	90
100×100×80	$4 \times 4 \times 3$	83	91
○ 125×125×20	$5 \times 5 \times \frac{3}{4}$	55	96
○ 125×125×25	$5 \times 5 \times 1$	60	97
○ 125×125×32	$5 \times 5 \times 1\frac{1}{4}$	62	100
○ 125×125×40	$5 \times 5 \times 1\frac{1}{2}$	66	100
○ 125×125×50	$5 \times 5 \times 2$	72	103
○ 125×125×65	$5 \times 5 \times 2\frac{1}{2}$	81	105
○ 125×125×80	$5 \times 5 \times 3$	87	107
○ 125×125×100	$5 \times 5 \times 4$	100	111
○ 150×150×25	$6 \times 6 \times 1$	64	110
○ 150×150×32	$6 \times 6 \times 1\frac{1}{4}$	67	113
○ 150×150×40	$6 \times 6 \times 1\frac{1}{2}$	70	115
○ 150×150×50	$6 \times 6 \times 2$	75	116
○ 150×150×65	$6 \times 6 \times 2\frac{1}{2}$	85	118
○ 150×150×80	$6 \times 6 \times 3$	92	120
○ 150×150×100	$6 \times 6 \times 4$	102	125
○ 150×150×125	$6 \times 6 \times 5$	116	128

12 プッシング (WS-BU)
Bushings

(呼び $\frac{3}{4}$ ~6)

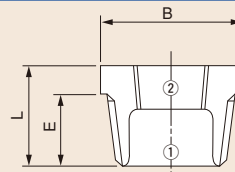

(単位: mm)

呼び径 (A)	呼 び ①×②	二面幅 B		L	E
		六角	八角		
20×15	$\frac{3}{4} \times \frac{1}{2}$	32		24	18
25×15	$1 \times \frac{1}{2}$	38		27	20
25×20	$1 \times \frac{3}{4}$	38		27	20
32×15	$1\frac{1}{4} \times \frac{1}{2}$	46		30	22
32×20	$1\frac{1}{4} \times \frac{3}{4}$	46		30	22
32×25	$1\frac{1}{4} \times 1$	46		30	22
40×15	$1\frac{1}{2} \times \frac{1}{2}$	54		32	23
40×20	$1\frac{1}{2} \times \frac{3}{4}$	54		32	23
40×25	$1\frac{1}{2} \times 1$	54		32	23
40×32	$1\frac{1}{2} \times 1\frac{1}{4}$	54		32	23
50×15	$2 \times \frac{1}{2}$		63	36	25
50×20	$2 \times \frac{3}{4}$		63	36	25
50×25	2×1		63	36	25
50×32	$2 \times 1\frac{1}{4}$		63	36	25
50×40	$2 \times 1\frac{1}{2}$		63	36	25
* 65×15	$2\frac{1}{2} \times \frac{1}{2}$		80	39	28
* 65×20	$2\frac{1}{2} \times \frac{3}{4}$		80	39	28
65×25	$2\frac{1}{2} \times 1$		80	39	28
65×32	$2\frac{1}{2} \times 1\frac{1}{4}$		80	39	28
65×40	$2\frac{1}{2} \times 1\frac{1}{2}$		80	39	28
65×50	$2\frac{1}{2} \times 2$		80	39	28
* 80×15	$3 \times \frac{1}{2}$		95	44	32
* 80×20	$3 \times \frac{3}{4}$		95	44	32

呼び径 (A)	呼 び ①×②	二面幅 B		L	E
		六角	八角		
80×25	3×1		95	44	32
80×32	$3 \times 1\frac{1}{4}$		95	44	32
80×40	$3 \times 1\frac{1}{2}$		95	44	32
80×50	3×2		95	44	32
80×65	$3 \times 2\frac{1}{2}$		95	44	32
* 100×15	$4 \times \frac{1}{2}$		120	51	37
* 100×20	$4 \times \frac{3}{4}$		120	51	37
* 100×25	4×1		120	51	37
* 100×32	$4 \times 1\frac{1}{4}$		120	51	37
100×40	$4 \times 1\frac{1}{2}$		120	51	37
100×50	4×2		120	51	37
100×65	$4 \times 2\frac{1}{2}$		120	51	37
100×80	4×3		120	51	37
* ○ 125×50	5×2		145	57	42
* ○ 125×65	$5 \times 2\frac{1}{2}$		145	57	42
○ 125×80	5×3		145	57	42
* ○ 150×32	$6 \times 1\frac{1}{4}$		170	64	46
* ○ 150×40	$6 \times 1\frac{1}{2}$		170	64	46
* ○ 150×50	6×2		170	64	46
* ○ 150×65	$6 \times 2\frac{1}{2}$		170	64	46
○ 150×80	6×3		170	64	46
○ 150×100	6×4		170	64	46
○ 150×125	6×5		170	64	46