
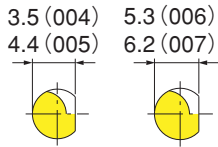


ピコカット

小径ソリッドバー

002、003、004、005、006、007 溝入れ、ボーリング用

スモールツール

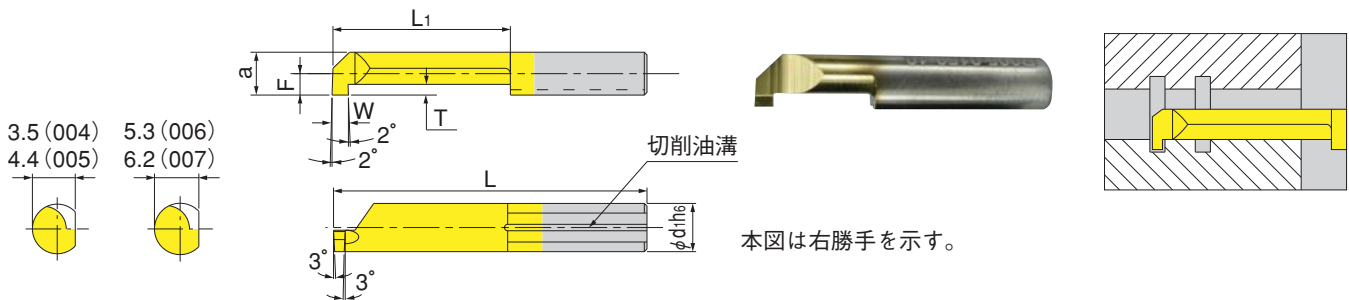

PICCO R/L 002/003/004/005/006/007 (溝入れ、ボーリング用)

販売単位：1個

型番	在庫				寸法(mm)								適合ホルダー
	R		L		W ^{±0.05}	F	a	L	L ₁	T _{max}	φD _{min}	φd ₁	
	IC228	IC908	IC228	IC908									
PICCO R/L 002.0050-5		●			0.5	0.2	1.8	19	5	0.4	2.0	4	PICCO...4-5 PICCO ACE...-4
PICCO R/L 002.0050-10		●			0.5	0.2	1.8	24	10	0.4	2.0	4	
PICCO R/L 002.0050-15		●			0.5	0.2	1.8	29	15	0.4	2.0	4	
PICCO R/L 003.0070-5		●			0.7	0.7	2.7	19	5	0.6	3.0	4	
PICCO R/L 003.0070-10		●			0.7	0.7	2.7	24	10	0.6	3.0	4	
PICCO R/L 003.0070-16		●			0.7	0.7	2.7	29	16	0.6	3.0	4	
PICCO R/L 004.0100-10	●		○		1.0	1.5	3.5	24	9	0.8	4.0	4	PICCO...4-5 PICCO ACE...-5
PICCO R/L 004.0100-16	●		○		1.0	1.5	3.5	30	15	0.8	4.0	4	
PICCO R/L 004.0100-20	●		○		1.0	1.5	3.5	34	19	0.8	4.0	4	
PICCO R/L 005.0100-10	●		○		1.0	1.9	4.4	25	9	1.0	5.0	5	
PICCO R/L 005.0100-15	●		○		1.0	1.9	4.4	30	14	1.0	5.0	5	
PICCO R/L 005.0100-20	●		○		1.0	1.9	4.4	35	19	1.0	5.0	5	
PICCO R/L 005.0100-25	●		○		1.0	1.9	4.4	40	24	1.0	5.0	5	PICCO...6-7 MG PCO...6 MG PCO...6-8 PICCO ACE...-6
PICCO R/L 005.0100-30	●		○		1.0	1.9	4.4	45	29	1.0	5.0	5	
PICCO R/L 005.0150-10	●		○		1.5	1.9	4.4	25	9	1.0	5.0	5	
PICCO R/L 005.0150-15	●		○		1.5	1.9	4.4	30	14	1.0	5.0	5	
PICCO R/L 005.0150-20	●		○		1.5	1.9	4.4	35	19	1.0	5.0	5	
PICCO R/L 005.0150-25	●		○		1.5	1.9	4.4	40	24	1.0	5.0	5	
PICCO R/L 005.0150-30	●		○		1.5	1.9	4.4	45	29	1.0	5.0	5	PICCO...6-7 PICCO ACE...-7
PICCO R/L 005.0200-10	●		○		2.0	1.9	4.4	25	9	1.0	5.0	5	
PICCO R/L 005.0200-15	●		○		2.0	1.9	4.4	30	14	1.0	5.0	5	
PICCO R/L 005.0200-20	●		○		2.0	1.9	4.4	35	19	1.0	5.0	5	
PICCO R/L 005.0200-25	●		○		2.0	1.9	4.4	40	24	1.0	5.0	5	
PICCO R/L 005.0200-30	●		○		2.0	1.9	4.4	45	29	1.0	5.0	5	
PICCO R/L 006.0100-10	●		○		1.0	2.3	5.3	25	9	1.8	6.0	6	PICCO...6-7 PICCO ACE...-7
PICCO R/L 006.0100-15	●		○		1.0	2.3	5.3	30	14	1.8	6.0	6	
PICCO R/L 006.0100-22	●		○		1.0	2.3	5.3	37	21	1.8	6.0	6	
PICCO R/L 006.0100-25	●		○		1.0	2.3	5.3	40	24	1.8	6.0	6	
PICCO R/L 006.0100-30	●		○		1.0	2.3	5.3	45	29	1.8	6.0	6	
PICCO R/L 006.0150-10	●		○		1.5	2.3	5.3	25	9	1.8	6.0	6	
PICCO R/L 006.0150-15	●		○		1.5	2.3	5.3	30	14	1.8	6.0	6	
PICCO R/L 006.0150-22	●		○		1.5	2.3	5.3	37	21	1.8	6.0	6	
PICCO R/L 006.0150-25	●		○		1.5	2.3	5.3	40	24	1.8	6.0	6	
PICCO R/L 006.0150-30	●		○		1.5	2.3	5.3	45	29	1.8	6.0	6	
PICCO R/L 006.0200-10	●		○		2.0	2.3	5.3	25	9	1.8	6.0	6	
PICCO R/L 006.0200-15	●		○		2.0	2.3	5.3	30	14	1.8	6.0	6	
PICCO R/L 006.0200-22	●		○		2.0	2.3	5.3	37	21	1.8	6.0	6	
PICCO R/L 006.0200-25	●		○		2.0	2.3	5.3	40	24	1.8	6.0	6	
PICCO R/L 006.0200-30	●		○		2.0	2.3	5.3	45	29	1.8	6.0	6	
PICCO R/L 007.0100-10	●		○		1.0	2.7	6.2	25	9	2.5	6.8	7	
PICCO R/L 007.0100-15	●		○		1.0	2.7	6.2	30	14	2.5	6.8	7	
PICCO R/L 007.0100-22	●		○		1.0	2.7	6.2	37	21	2.5	6.8	7	
PICCO R/L 007.0100-25	●		○		1.0	2.7	6.2	40	24	2.5	6.8	7	
PICCO R/L 007.0100-30	●		○		1.0	2.7	6.2	45	29	2.5	6.8	7	
PICCO R/L 007.0150-10	●		○		1.5	2.7	6.2	25	9	2.5	6.8	7	
PICCO R/L 007.0150-15	●		○		1.5	2.7	6.2	30	14	2.5	6.8	7	
PICCO R/L 007.0150-22	●		○		1.5	2.7	6.2	37	21	2.5	6.8	7	
PICCO R/L 007.0150-25	●		○		1.5	2.7	6.2	40	24	2.5	6.8	7	
PICCO R/L 007.0150-30	●		○		1.5	2.7	6.2	45	29	2.5	6.8	7	
PICCO R/L 007.0200-10	●		○		2.0	2.7	6.2	25	9	2.5	6.8	7	
PICCO R/L 007.0200-15	●		○		2.0	2.7	6.2	30	14	2.5	6.8	7	
PICCO R/L 007.0200-22	●		○		2.0	2.7	6.2	37	21	2.5	6.8	7	
PICCO R/L 007.0200-25	●		○		2.0	2.7	6.2	40	24	2.5	6.8	7	
PICCO R/L 007.0200-30	●		○		2.0	2.7	6.2	45	29	2.5	6.8	7	

適合ホルダーはB17~B19頁をご参照下さい。