


ピコカット

小径ソリッドバー

004、005、006、007フルRタイプ / 047倣い用 / 050倣い、ボーリング用

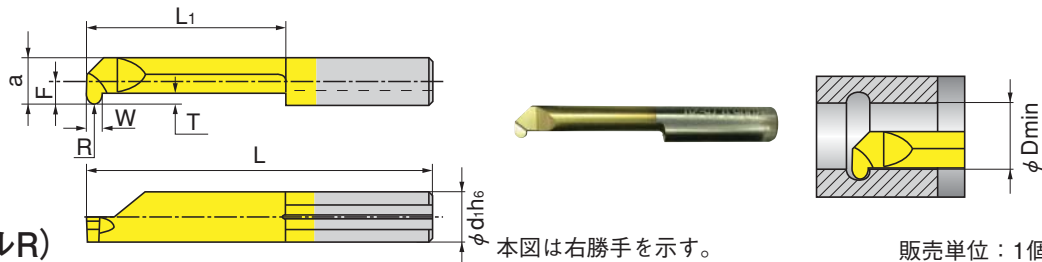

スモールツール


PICCO R/L (フルR)

本図は右勝手を示す。

販売単位：1個

型番	在庫		寸法(mm)								適合ホルダー	
	R	L	W±0.05	R	F	a	L	L ₁	Tmax	φ Dmin		φ d ₁
PICCO R/L 004.0.50-16	●		1.0	0.50	1.5	3.5	30	15	0.8	4.0	4	PICCO...4-5、PICCO ACE...-4
PICCO R/L 005.0.50-20	●		1.0	0.50	1.9	4.4	35	19	1.0	5.0	5	PICCO...4-5 PICCO ACE...-5
PICCO R/L 005.0.75-20	●		1.5	0.75	1.9	4.4	35	19	1.0	5.0	5	PICCO...4-5 PICCO ACE...-5
PICCO R/L 005.1.00-20	●		2.0	1.00	1.9	4.4	35	19	1.0	5.0	5	PICCO...4-5 PICCO ACE...-5
PICCO R/L 006.0.50-25	●		1.0	0.50	2.3	5.3	40	24	1.8	6.0	6	PICCO...6-7 MG PCO...6/6-8 PICCO ACE...-6
PICCO R/L 006.0.75-25	●		1.5	0.75	2.3	5.3	40	24	1.8	6.0	6	PICCO...6-7 MG PCO...6/6-8 PICCO ACE...-6
PICCO R/L 006.1.00-25	●		2.0	1.00	2.3	5.3	40	24	1.8	6.0	6	PICCO...6-7 MG PCO...6/6-8 PICCO ACE...-6
PICCO R/L 007.0.50-30	●		1.0	0.50	2.7	6.3	45	29	2.5	6.8	7	PICCO...6-7 PICCO ACE...-7
PICCO R/L 007.0.75-30	●		1.5	0.75	2.7	6.3	45	29	2.5	6.8	7	PICCO...6-7 PICCO ACE...-7
PICCO R/L 007.1.00-30	●		2.0	1.00	2.7	6.3	45	29	2.5	6.8	7	PICCO...6-7 PICCO ACE...-7

左勝手は受注生産。

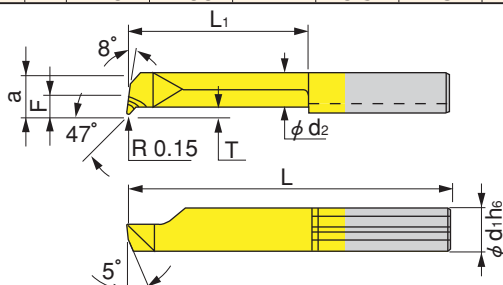


本図は右勝手を示す。

PICCO R/L 047 (倣い用)

販売単位：1個

型番	在庫		寸法(mm)							適合ホルダー	
	R	L	F	a	L	L ₁	φ d ₂	Tmax	φ Dmin		φ d ₁
PICCO R/L 047.4-20	●		1.5	3.5	34	20	3.0	0.3	4.0	4	PICCO...4-5、PICCO ACE...-4
PICCO R/L 047.5-25	●		1.9	4.4	40	25	3.8	0.5	5.0	5	PICCO...4-5、PICCO ACE...-5
PICCO R/L 047.6-30	●		2.3	5.3	45	30	4.5	0.5	6.0	6	PICCO...6-7、MG PCO...6/6-8、PICCO ACE...-6

左勝手は受注生産。

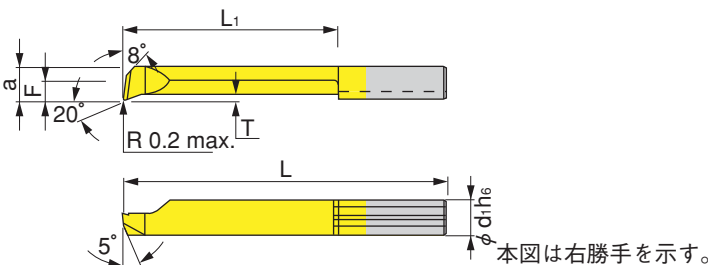

本図は右勝手を示す。

PICCO R/L 050...C (倣い、ボーリング用/ブレーカー付)

販売単位：1個

型番	在庫		寸法(mm)							適合ホルダー
	R	L	F	a	L	L ₁	Tmax	φ Dmin	φ d ₁	
PICCO R/L 050.4-10C	●		1.5	3.5	24	10	0.3	4.0	4	PICCO...4-5 PICCO ACE...-4
PICCO R/L 050.4-20C	●		1.5	3.5	34	20	0.3	4.0	4	
PICCO R/L 050.4-24C	▲		1.5	3.5	38	24	0.3	4.0	4	
PICCO R/L 050.4-28C	●		1.5	3.5	42	28	0.3	4.0	4	PICCO...4-5 PICCO ACE...-5
PICCO R/L 050.5-10C	▲		1.9	4.4	25	10	0.5	5.0	5	
PICCO R/L 050.5-15C	●		1.9	4.4	30	15	0.5	5.0	5	
PICCO R/L 050.5-20C	●		1.9	4.4	35	20	0.5	5.0	5	PICCO...4-5 PICCO ACE...-5
PICCO R/L 050.5-25C	●		1.9	4.4	40	25	0.5	5.0	5	
PICCO R/L 050.5-30C	▲		1.9	4.4	45	30	0.5	5.0	5	
PICCO R/L 050.5-35C	●		1.9	4.4	50	35	0.5	5.0	5	PICCO...4-5 PICCO ACE...-5
PICCO R/L 050.6-15C	●		2.3	5.3	30	15	0.5	6.0	6	
PICCO R/L 050.6-22C	●		2.3	5.3	37	22	0.5	6.0	6	
PICCO R/L 050.6-25C	●		2.3	5.3	40	25	0.5	6.0	6	PICCO...6-7 MG PCO...6 MG PCO...6-8 PICCO ACE...-6
PICCO R/L 050.6-30C	●		2.3	5.3	45	30	0.5	6.0	6	
PICCO R/L 050.6-35C	●		2.3	5.3	50	35	0.5	6.0	6	
PICCO R/L 050.6-42C	●		2.3	5.3	57	42	0.5	6.0	6	PICCO...6-7 MG PCO...6 MG PCO...6-8 PICCO ACE...-6
PICCO R/L 050.7-20C	●		2.8	6.3	35	20	0.6	6.8	7	
PICCO R/L 050.7-25C	●		2.8	6.3	40	25	0.6	6.8	7	
PICCO R/L 050.7-30C	▲		2.8	6.3	45	30	0.6	6.8	7	PICCO...6-7 PICCO ACE...-7
PICCO R/L 050.7-35C	▲		2.8	6.3	50	35	0.6	6.8	7	
PICCO R/L 050.7-40C	▲		2.8	6.3	55	40	0.6	6.8	7	

左勝手は受注生産。

適合ホルダーはB17~B19頁をご参照下さい。