
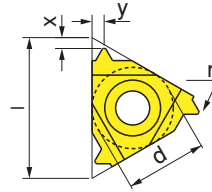


## ISOメートルねじ切りチップ(ISO) 仕上刃(さらえ刃)付タイプ

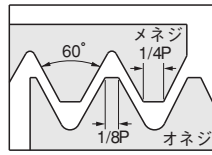

### ISO 外径ねじ用

販売単位：5個

形状	型番	用途		寸法(mm)					PVDコーティング					超微粒子超硬
		ピッチ	山数	d	l	r	x	y	IC228	IC808	IC908	IC1007	IC08	
ERチップ	11ER 0.50 ISO	0.50	—	6.350	11	0.05	0.6	0.6			●			
	11ER 0.70 ISO	0.70	—	6.350	11	0.07	0.6	0.6			●			
	11ER 0.80 ISO	0.80	—	6.350	11	0.09	0.6	0.6			●			
	11ER 1.00 ISO	1.00	—	6.350	11	0.12	0.7	0.7			●			
	11ER 1.50 ISO	1.50	—	6.350	11	0.18	0.8	1.0			●			
	11ER 1.75 ISO	1.75	—	6.350	11	0.21	0.8	1.1						
	16ER 0.35 ISO	0.35	—	9.525	16	0.04	0.8	0.4			○			
	16ER 0.40 ISO	0.40	—	9.525	16	0.04	0.7	0.4			○			
	16ER 0.50 ISO	0.50	—	9.525	16	0.04	0.6	0.6			●			
	16ER 0.60 ISO	0.60	—	9.525	16	0.07	0.6	0.6			●			
	16ER 0.70 ISO	0.70	—	9.525	16	0.07	0.6	0.6			●			
	16ER 0.75 ISO	0.75	—	9.525	16	0.08	0.6	0.6			●			
	16ER 0.80 ISO	0.80	—	9.525	16	0.09	0.6	0.6			●			
	16ER 1.00 ISO	1.00	—	9.525	16	0.12	0.7	0.7			●	▲		
	16ER 1.25 ISO	1.25	—	9.525	16	0.15	0.8	0.9			●			
	16ER 1.50 ISO	1.50	—	9.525	16	0.18	0.8	1.0		▲	●	▲		
16ER 1.75 ISO	1.75	—	9.525	16	0.21	0.9	1.2			●				
16ER 2.00 ISO	2.00	—	9.525	16	0.25	1.0	1.3			●	▲			
16ER 2.50 ISO	2.50	—	9.525	16	0.31	1.1	1.5			●				
16ER 3.00 ISO	3.00	—	9.525	16	0.38	1.2	1.6			●				
22ER 3.50 ISO	3.50	—	12.700	22	0.44	1.6	2.3			●				
22ER 4.00 ISO	4.00	—	12.700	22	0.52	1.6	2.3			●				
22ER 4.50 ISO	4.50	—	12.700	22	0.58	1.7	2.4			●				
22ER 5.00 ISO	5.00	—	12.700	22	0.64	1.7	2.5			●				
22ER 6.00 ISO	6.00	—	12.700	22	0.78	2.0	2.7							
16ERB 0.80 ISO	0.80	—	9.525	16	0.09	0.6	0.6			●				
16ERB 1.00 ISO	1.00	—	9.525	16	0.12	0.7	0.7			●				
16ERB 1.25 ISO	1.25	—	9.525	16	0.15	0.8	0.9			●				
16ERB 1.50 ISO	1.50	—	9.525	16	0.18	0.8	1.0			●				
16ERB 1.75 ISO	1.75	—	9.525	16	0.21	0.9	1.2			●				
16ERB 2.00 ISO	2.00	—	9.525	16	0.25	1.0	1.3			●				
16ERB 2.50 ISO	2.50	—	9.525	16	0.31	1.1	1.5			●				
16ERB 3.00 ISO	3.00	—	9.525	16	0.38	1.2	1.6			●				
16ERM 0.75 ISO	0.75	—	9.525	16	0.08	0.6	0.6		●	●				
16ERM 1.00 ISO	1.00	—	9.525	16	0.11	0.7	0.7		●	●	▲			
16ERM 1.25 ISO	1.25	—	9.525	16	0.14	0.8	0.9		●	●	▲			
16ERM 1.50 ISO	1.50	—	9.525	16	0.19	0.8	1.0		●	●	▲			
16ERM 1.75 ISO	1.75	—	9.525	16	0.20	0.9	1.2		●	●	▲			
16ERM 2.00 ISO	2.00	—	9.525	16	0.24	1.0	1.3		●	●	▲			
16ERM 2.50 ISO	2.50	—	9.525	16	0.30	1.1	1.5		●	●	▲			
16ERM 3.00 ISO	3.00	—	9.525	16	0.38	1.2	1.6		●	●	▲			
22ERM 3.50 ISO	3.50	—	12.700	22	0.48	1.6	2.3		●	●				
22ERM 4.00 ISO	4.00	—	12.700	22	0.55	1.6	2.3		●	●				

ねじ切り工具