




## ヘリ2000 (15mm切刃)

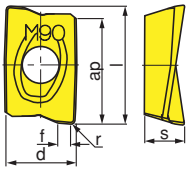


HM90 ADCR

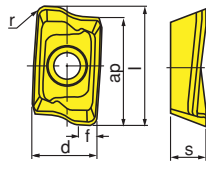


HM90 ADKT 1505PDR/NM ADKT...

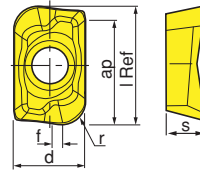

HM90 ADKT 1505〇〇-PDR

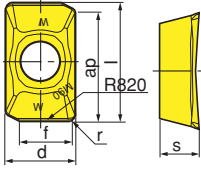

HM90...-W

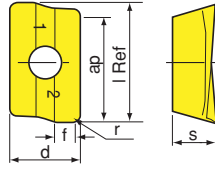

HM90 ADKW

### HM90 AD.../NM ADKT

販売単位：10個

型番	寸法 (mm)						PVDコーティング										CVDコーティング	超硬	超微粒超硬	
	d	l	ap	s	f	r	IC328	IC330	IC380	IC808	IC810	IC830	IC908	IC910	IC928	IC950				IC4050
HM90 ADCR 1505PDR-P	9.550	16.30	15.30	6.90	4.00	0.8									●				●	●
HM90 ADCT 150508PDTR	9.500	15.70	14.00	6.40	4.10	0.8		●				●								
HM90 ADCT 1505PDR-CF	9.300	15.70	14.00	6.40	4.20	0.8			●			●								
HM90 ADCT 1505PDR-PL	9.650	16.18	14.50	5.85	2.16	0.8				▲		●								
HM90 ADCT 150508R-T	9.650	16.18	14.50	5.85	2.16	0.8			●											
HM90 ADCT 150516R-T	9.650	16.18	14.50	5.85	2.16	1.6				▲										
HM90 ADCT 150520R-T	9.650	16.18	14.50	5.85	2.16	2.0				▲										
HM90 ADCT 150524R-T	9.650	16.18	14.50	5.85	2.16	2.4				▲										
HM90 ADCT 150532R-T	9.650	16.18	14.50	5.85	2.16	3.2				▲										
HM90 ADCT 150540R-T	9.650	16.18	14.50	5.85	2.16	4.0				▲										
HM90 ADCT 150550R-T	9.650	16.18	14.50	5.85	2.16	5.0				▲										
HM90 ADKT 1505PDR	9.650	16.18	14.50	5.85	2.16	0.8	●	●		●	●	●	●	●	●	●	●			
HM90 ADKT 1505PDR-MM	9.600	16.00	14.50	5.80	2.70	0.8						●								
HM90 ADKT 150516-PDR	9.650	15.60	14.20	5.92	1.37	1.6							●							
HM90 ADKT 150520-PDR	9.650	15.60	14.20	5.90	0.79	2.0							●							
HM90 ADKT 150524-PDR	9.650	15.60	14.20	5.80	0.52	2.4							●							
HM90 ADKT 150532-PDR	9.650	15.20	14.10	5.85	—	3.2							●							
HM90 ADKT 150540-PDR	9.650	14.85	13.95	5.80	—	4.0							●							
HM90 ADKT 150550-PDR	9.650	14.85	13.80	5.75	—	5.0							●							
HM90 ADKT 150564-PDR	9.650	14.85	13.66	5.65	—	6.4							●							
HM90 ADKT 1505PD-W	9.520	16.75	15.00	5.83	5.90	0.8							●		●					
HM90 ADKW 1505PDR	9.590	16.15	14.15	5.83	2.45	0.8							●	○	●					
NM ADKT 1505PDR	9.650	16.10	14.50	5.85	2.20	0.8									●					

ミーリング工具