


# SBU·SNP

ねじ込み形管継手


## SBU ブッシング

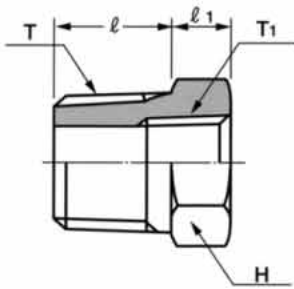

単位: mm

継手の呼び	T×T <sub>1</sub> (R×Rc)	H (六角)	l	l <sub>1</sub>	重量 (kg)
SBU03-020F	3/8 × 1/4	19	14	8	0.025
SBU04-020F	1/2 × 1/4	24	17	9	0.06
SBU04-030F	1/2 × 3/8	24	17	9	0.046
SBU06-020F	3/4 × 1/4	30	19	10	0.12
SBU06-030F	3/4 × 3/8	30	19	10	0.10
SBU06-040F	3/4 × 1/2	30	19	10	0.079
SBU08-020F	1 × 1/4	36	22	11	0.22
SBU08-030F	1 × 3/8	36	22	11	0.20
SBU08-040F	1 × 1/2	36	22	11	0.18
SBU08-060F	1 × 3/4	36	22	11	0.13
SBU10-040F	1 1/4 × 1/2	46	24	12	0.37
SBU10-060F	1 1/4 × 3/4	46	24	12	0.31
SBU10-080F	1 1/4 × 1	46	24	12	0.23
SBU12-040F	1 1/2 × 1/2	50	24	14	0.51
SBU12-060F	1 1/2 × 3/4	50	24	14	0.46
SBU12-080F	1 1/2 × 1	50	24	14	0.37
SBU12-100F	1 1/2 × 1 1/4	50	24	14	0.22
SBU16-060F	2 × 3/4	65	28	16	0.94
SBU16-080F	2 × 1	65	28	16	0.90
SBU16-100F	2 × 1 1/4	65	28	16	0.68
SBU16-120F	2 × 1 1/2	65	28	16	0.54

## SNP ニップル

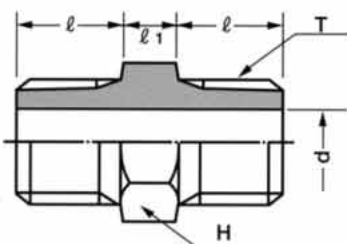

単位: mm

継手の呼び	T (R)	d	H	l	l <sub>1</sub>	重量 (kg)
SNP01-000J	1/8	4	12	9	6	0.013
SNP02-000F	1/4	7	17	13	8	0.032
SNP03-000F	3/8	9	19	14	8	0.048
SNP04-000F	1/2	12	24	17	9	0.083
SNP06-000F	3/4	16	30	19	10	0.14
SNP08-000F	1	20	36	22	11	0.26
SNP10-000F	1 1/4	28	46	24	12	0.41
SNP12-000F	1 1/2	32	50	24	14	0.53
SNP16-000F	2	40	65	28	16	0.99