


# IHARA スイベルジョイント：SJM形


## 取付形状

接続部の形状は、機器及びホースの金具の形状により対応可能です。

接続部の形状例を下図に示します。

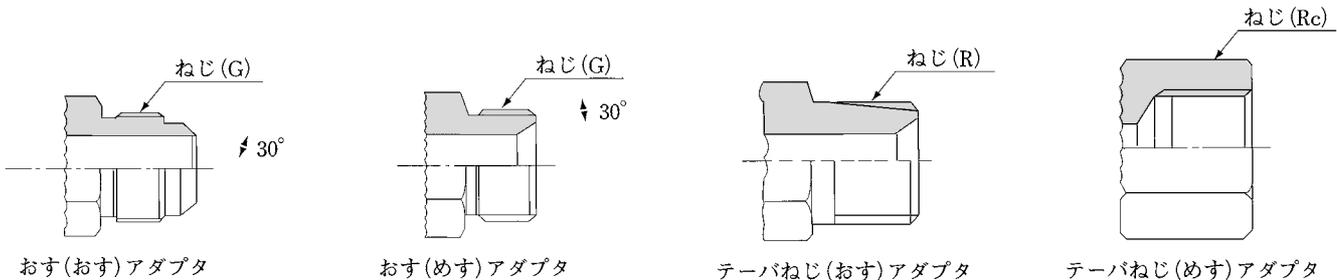


| 呼び         | (R)<br>T | d    | D    | (約)<br>L | 六角対辺 |    | 基準径の<br>位置 G |
|------------|----------|------|------|----------|------|----|--------------|
|            |          |      |      |          | H    | H1 |              |
| SJM402-402 | 1/4      | 5    | 25.5 | 64       | 22   | 14 | 6.01         |
| SJM403-403 | 3/8      | 8    | 28.5 | 75       | 22   | 19 | 6.35         |
| SJM404-404 | 1/2      | 11.5 | 33   | 85       | 27   | 22 | 8.16         |
| SJM406-406 | 3/4      | 16   | 42   | 97       | 36   | 30 | 9.53         |
| SJM408-408 | 1        | 20   | 47.5 | 107      | 41   | 36 | 10.39        |
| SJM410-410 | 1・1/4    | 26   | 58   | 126.5    | 50   | 46 | 12.70        |

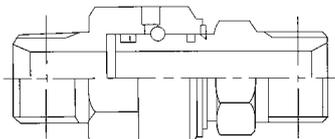


※印サイズの形状

| 呼び         | (R×Rc)<br>T | d    | D    | (約)<br>L | 六角対辺 |    | 基準径の<br>位置 G |
|------------|-------------|------|------|----------|------|----|--------------|
|            |             |      |      |          | H    | H1 |              |
| SJM402-502 | 1/4         | 5    | 25.5 | 61       | 22   | 19 | 6.01         |
| SJM403-503 | 3/8         | 8    | 28.5 | 72       | 22   | 24 | 6.35         |
| SJM404-504 | 1/2         | 11.5 | 33   | 82       | 27   | 30 | 8.16         |
| SJM406-506 | 3/4         | 16   | 42   | 94       | 36   | 36 | 9.53         |
| SJM408-508 | 1           | 20   | 47.5 | 104      | 41   | 46 | 10.39        |
| SJM410-510 | 1・1/4       | 26   | 58   | 123.5    | 50   | 55 | 12.70        |

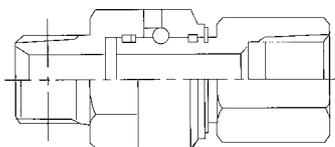


※印サイズの形状

| 呼び         | (Rc)<br>T | d    | D    | (約)<br>L | 六角対辺 |    |
|------------|-----------|------|------|----------|------|----|
|            |           |      |      |          | H    | H1 |
| SJM502-502 | 1/4       | 5    | 25.5 | 62       | 22   | 19 |
| SJM503-503 | 3/8       | 8    | 28.5 | 73       | 24   | 24 |
| SJM504-504 | 1/2       | 11.5 | 33   | 84       | 30   | 30 |
| SJM506-506 | 3/4       | 16   | 42   | 94       | 36   | 36 |
| SJM508-508 | 1         | 20   | -    | 105      | 50   | 46 |
| SJM510-510 | 1・1/4     | 26   | -    | 124      | 60   | 55 |

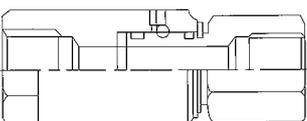


※印サイズの形状

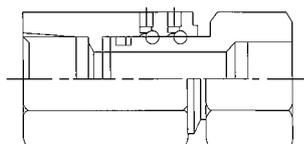


☆印サイズの形状

## SJM4 - 4

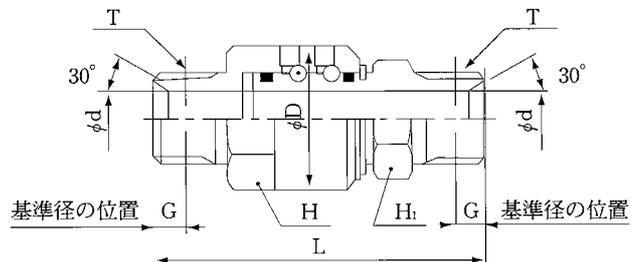

## SJM4 - 5

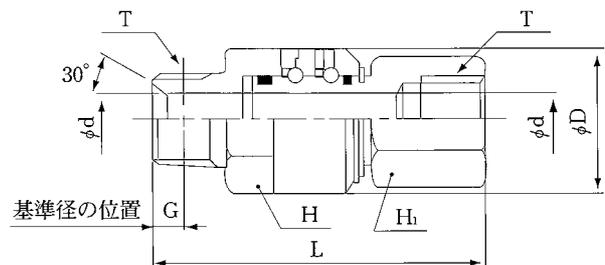

## SJM5 - 5

