


ALCK-R
(Reamed)

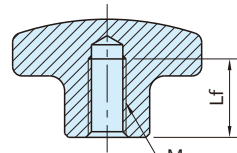

ALCK-T
(Tapped)

Body
Aluminum alloy(AC4B)
Buffed finish

Part Number		D	H	D ₁	S	d (H9)	M	Lf	Weight (g)
Reamed	Tapped								
ALCK40R	ALCK40T	40	25	14	14	8	M 8×1.25	15	30
ALCK50R	ALCK50T	50	32	18	20	10	M10×1.5	18	60
ALCK63R	ALCK63T	63	40	25	25	12	M12×1.75	22	90
ALCK80R	ALCK80T	80	50	26.5	30	16	M16×2	28	180

Notes

Dimensions are subject to slight variations due to buffed finish.