

# PB / PC


# PLASTIC BALL KNOBS



**PB**-R  
(Without Insert, Red)



**PC**-B  
(With Insert, Black)

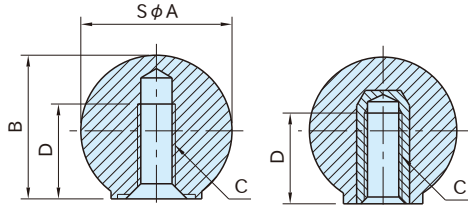

**PB**  
(Without Insert)

**PC**  
(With Insert)

Body	Insert(PC only)
ABS plastic R:Red, B:Black	Brass (C3604B)

## **PB** (Without Insert)

Red	Black	A	B	C	D	Weight (g)
Part Number	Part Number					
<b>PB20× 5R</b>	<b>PB20× 5B</b>	20	19	M 5×0.8	10	5
<b>PB20× 6R</b>	<b>PB20× 6B</b>			M 6×1		
<b>PB25× 6R</b>	<b>PB25× 6B</b>	25	24	M 8×1.25	14	10
<b>PB25× 8R</b>	<b>PB25× 8B</b>					
<b>PB32× 8R</b>	<b>PB32× 8B</b>	32	30	M10×1.5	20	20
<b>PB32×10R</b>	<b>PB32×10B</b>					
<b>PB40×10R</b>	<b>PB40×10B</b>	40	38	M12×1.75	22	40
<b>PB40×12R</b>	<b>PB40×12B</b>					
<b>PB50×12R</b>	<b>PB50×12B</b>	50	48	M16×2	25	85
<b>PB50×16R</b>	<b>PB50×16B</b>					

## **PC** (With Insert)

Red	Black	A	B	C	D	Weight (g)
Part Number	Part Number					
<b>PC20× 5R</b>	<b>PC20× 5B</b>	20	19	M 5×0.8	8	7
<b>PC20× 6R</b>	<b>PC20× 6B</b>			M 6×1		
<b>PC25× 6R</b>	<b>PC25× 6B</b>	25	24	M 8×1.25	12	15
<b>PC25× 8R</b>	<b>PC25× 8B</b>					
<b>PC32× 8R</b>	<b>PC32× 8B</b>	32	30	M10×1.5	15	25
<b>PC32×10R</b>	<b>PC32×10B</b>					
<b>PC40×10R</b>	<b>PC40×10B</b>	40	38	M12×1.75	18	30
<b>PC40×12R</b>	<b>PC40×12B</b>					
<b>PC50×12R</b>	<b>PC50×12B</b>	50	48	M16×2	25	55
<b>PC50×16R</b>	<b>PC50×16B</b>					

- A slightly tapered tapped hole in the **PB** knobs provides positive lock.
- If an adhesive agent is applied, it should be adaptive to the ABS plastic.
- Use in hot or highly humid circumstances can deteriorate the plastic material properties.