


SIS-SUS

STAINLESS STEEL IDLE SPROCKETS

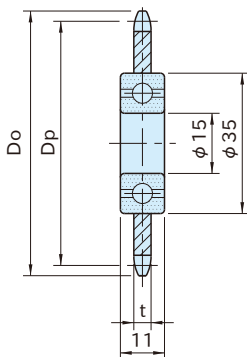

Sprocket	Bearing
Stainless steel(SUS304)	Stainless steel

Part Number	Chain No.	No. of Teeth	Do	Dp	t	Bearing	Weight (g)	Proper Idler Pin
SIS320-SUS	35	20	66	60.89	4.3	SS6202-2RS	110	PID1511
SIS417-SUS	40	17	75	69.12	7.2		200	
SIS516-SUS	50	16	89	81.37	8.7		320	
SIS614-SUS	60	14	95	85.61	11.7		480	

Features

Available with pressed-in ball bearing

Reference

·TENSIONER ASSEMBLY EXAMPLES

Technical Information

Allowable Bearing Radial Loads(N)<for 3,000 hours of average service life>

Bearing	Speed (min ⁻¹)					
	100	200	300	500	1000	1500
SS6202-2RS	2310	1830	1610	1350	1080	940