


TC-IB

IDLER SCREWS

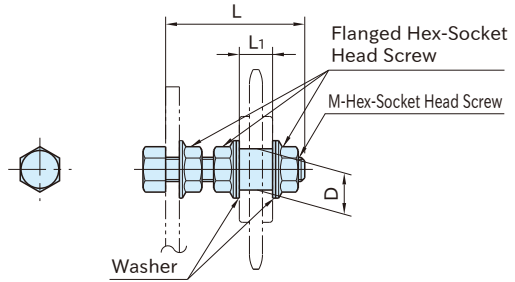

Screw & Nuts & Washer	Collar
Stainless steel (SUS304)	Stainless steel (SUS303)

Part Number	M	L	D	L ₁	Weight (g)	Proper Tighteners
TC-IB08045A	M 8	45	15	11	49	TC-RE10 TC-PX10
TC-IB08045B			12	10	43	
TC-IB08045C			10	8	40	
TC-IB08045			-	-	38	
TC-IB10055A	M10	55	15	11	73	TC-RE20 TC-PX20 TC-RE30 TC-PX30
TC-IB10055B			12	10	67	
TC-IB10055			-	-	64	
TC-IB10070A			15	11	81	
TC-IB10070B	M10	70	12	10	75	TC-RE30 TC-PX30
TC-IB10070			-	-	72	
TC-IB12100A			15	11	140	
TC-IB12100	M12	100	-	-	134	TC-RE40

Part Number	Proper Idle Sprockets
TC-IB08045A	SIS320, SIS320UU, SIS320-SUS
TC-IB08045B	SIS318
TC-IB08045C	SIS316
TC-IB08045	-
TC-IB10055A	SIS320, SIS320UU, SIS320-SUS, SIS417, SIS417UU, SIS417-SUS, SIS516, SIS516UU, SIS516-SUS, SIS614, SIS614UU, SIS614-SUS, BIS320
TC-IB10055B	SIS318, SIS415, SIS514, SIS612
TC-IB10055	SIS316, SIS412, SIS512, SIS610
TC-IB10070A	SIS320, SIS320UU, SIS320-SUS, SIS417, SIS417UU, SIS417-SUS, SIS516, SIS516UU, SIS516-SUS, SIS614, SIS614UU, SIS614-SUS, BIS320
TC-IB10070B	SIS318, SIS415, SIS514, SIS612
TC-IB10070	SIS316, SIS412, SIS512, SIS610
TC-IB12100A	SIS516, SIS516UU, SIS516-SUS, SIS614, SIS614UU, SIS614-SUS, SIS809
TC-IB12100	SIS514, SIS612