


形状・寸法

■ クロス X

X

304(SCS 13A)

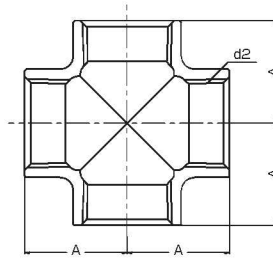


呼び径		ねじ	寸法 (mm)		304 在庫
A (mm)	B (inch)	d2	A		
8	1/4	Rc 1/4	19		●
10	3/8	Rc 3/8	23		●
15	1/2	Rc 1/2	27		●
20	3/4	Rc 3/4	32		●
25	1	Rc 1	38		●
32	1 1/4	Rc 1 1/4	45		●
40	1 1/2	Rc 1 1/2	48		●
50	2	Rc 2	57		●

■ 四角プラグ P

P

304(SUS 304 または SCS 13A)
316(SUS 316 または SUS F316)

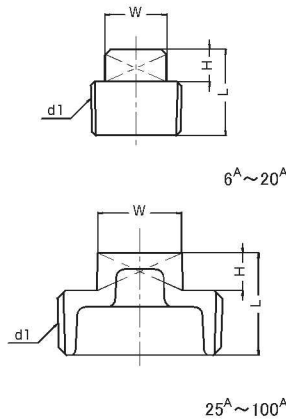


呼び径		ねじ	寸法 (mm)			304 在庫	316 在庫
A (mm)	B (inch)	d1	H	L	W		
6	1/8	R 1/8	7	16	7	●	●
8	1/4	R 1/4	8	20	9	●	●
10	3/8	R 3/8	9	22	12	●	●
15	1/2	R 1/2	10	26	14	●	●
20	3/4	R 3/4	9	27	17	●	●
25	1	R 1	12	32	18.5	●	●
32	1 1/4	R 1 1/4	12	34	22.5	●	—
40	1 1/2	R 1 1/2	13	35	25.5	●	—
50	2	R 2	14	40	31.5	●	—
65	2 1/2	R 2 1/2	16	46	41	●	—
80	3	R 3	16	50	46	●	—
100	4	R 4	20	60	58	●	—

■ 六角プラグ STP

STP

304(SUS 304)

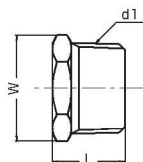

呼び径		ねじ	寸法 (mm)			304 在庫
A (mm)	B (inch)	d1	L	W		
				六角	八角	
6	1/8	R 1/8	16	12	—	●
8	1/4	R 1/4	19	14	—	●
10	3/8	R 3/8	22	17	—	●
15	1/2	R 1/2	24	22	—	●
20	3/4	R 3/4	27	—	27	●
25	1	R 1	30	—	34	●