


形状・寸法

■ ソケットストレート(厚口) SJ


304(SUS 304TKA)

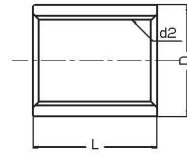


呼び径		ねじ d2	寸法(mm)		304 在庫
A (mm)	B (inch)		D	L	
8	1/4	Rp1/4	19	27	●
10	3/8	Rp3/8	23	28	●
15	1/2	Rp1/2	28	37	●
20	3/4	Rp3/4	34.5	39	●
25	1	Rp1	41.5	46	●
32	1 1/4	Rp1 1/4	51	51	●
40	1 1/2	Rp1 1/2	58	51	●
50	2	Rp2	70	60	●

■ 径違いソケット RS

304(SUS 304 または SCS 13A)

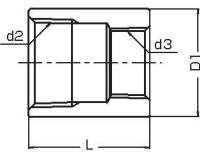

8 × 6<sup>A</sup> ~ 10 × 8<sup>A</sup>

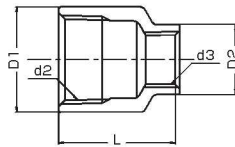


15 × 8<sup>A</sup> ~ 50 × 40<sup>A</sup>

呼び径		ねじ		寸法(mm)			304 在庫
A (mm)	B (inch)	d2	d3	D1	D2	L	
8 × 6	1/4 × 1/8	Rc1/4	Rc1/8	19	—	29	●
10 × 6	3/8 × 1/8	Rc3/8	Rc1/8	22	—	30	●
10 × 8	3/8 × 1/4	Rc3/8	Rc1/4	22	—	30	●
15 × 8	1/2 × 1/4	Rc1/2	Rc1/4	26	19	38	●
15 × 10	1/2 × 3/8	Rc1/2	Rc3/8	26	21.5	38	●
20 × 10	3/4 × 3/8	Rc3/4	Rc3/8	32	21.5	40	●
20 × 15	3/4 × 1/2	Rc3/4	Rc1/2	32	26	40	●
25 × 15	1 × 1/2	Rc1	Rc1/2	39	26	45	●
25 × 20	1 × 3/4	Rc1	Rc3/4	39	32	45	●
32 × 20	1 1/4 × 3/4	Rc1 1/4	Rc3/4	48.5	32	51	●
32 × 25	1 1/4 × 1	Rc1 1/4	Rc1	48.5	39	51	●
40 × 25	1 1/2 × 1	Rc1 1/2	Rc1	54.5	39	54	●
40 × 32	1 1/2 × 1 1/4	Rc1 1/2	Rc1 1/4	54.5	48.5	54	●
50 × 25	2 × 1	Rc2	Rc1	67	39	64	●
50 × 32	2 × 1 1/4	Rc2	Rc1 1/4	67	48.5	64	●
50 × 40	2 × 1 1/2	Rc2	Rc1 1/2	67	54.5	64	●

■ 六角ソケット STS


304(SUS 304)

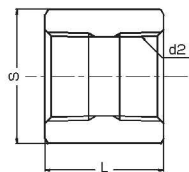

呼び径		ねじ d2	寸法(mm)	304 在庫		
A (mm)	B (inch)				L	S
					六角	八角
8	1/4	Rc1/4	25	19	—	●
10	3/8	Rc3/8	28	23	—	●
15	1/2	Rc1/2	34	29	—	●
20	3/4	Rc3/4	38	—	34	●
25	1	Rc1	44	46	—	●

■ 両ニップル N

304(SUS 304 TP)  
316(SUS 316 TP)

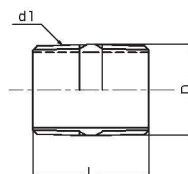

呼び径		ねじ d1	寸法(mm)		304 在庫	316 在庫
A (mm)	B (inch)		D	L		
6	1/8	R1/8	10.5	20	●	●
8	1/4	R1/4	13.8	26	●	●
10	3/8	R3/8	17.3	28	●	●
15	1/2	R1/2	21.7	34	●	●
20	3/4	R3/4	27.2	38	●	●
25	1	R1	34.0	43	●	●
32	1 1/4	R1 1/4	42.7	50	●	●
40	1 1/2	R1 1/2	48.6	50	●	●
50	2	R2	60.5	58	●	●
65	2 1/2	R2 1/2	76.3	70	●	—
80	3	R3	89.1	78	●	—
100	4	R4	114.3	90	●	—