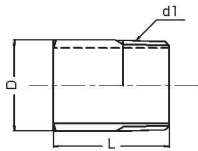


形状・寸法

■ 片ニップル


NS

304(SUS 304 TP)
316(SUS 316 TP)

呼び径		ねじ	寸法(mm)		304 在庫	316 在庫
A (mm)	B (inch)		D	L		
6	1/8	R1/8	10.5	20	●	●
8	1/4	R1/4	13.8	26	●	●
10	3/8	R3/8	17.3	28	●	●
15	1/2	R1/2	21.7	34	●	●
20	3/4	R3/4	27.2	38	●	●
25	1	R1	34.0	43	●	●
32	1 1/4	R1 1/4	42.7	50	●	●
40	1 1/2	R1 1/2	48.6	50	●	●
50	2	R2	60.5	58	●	●
65	2 1/2	R2 1/2	76.3	70	●	—
80	3	R3	89.1	78	●	—
100	4	R4	114.3	90	●	—

■ 六角ニップル

STN

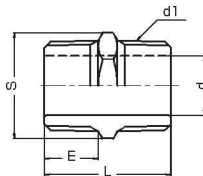
304(SUS 304 または SCS 13A)
316(SUS 316)

呼び径		ねじ	寸法(mm)					304 在庫	316 在庫	
A (mm)	B (inch)		d1	L	E	d	S			
							六角	八角	十角	
6	1/8	R1/8	28	10	5	12	—	—	—	●
8	1/4	R1/4	34	12	7	14	—	—	—	●
10	3/8	R3/8	36	13	8.5	17	—	—	—	●
15	1/2	R1/2	42	16	14.5	22	—	—	—	●
20	3/4	R3/4	47	18	19.5	—	27.5	—	—	●
25	1	R1	52	20	25	—	34.5	—	—	●
32	1 1/4	R1 1/4	56	22	33.5	—	43.5	—	—	●
40	1 1/2	R1 1/2	60	23	39	—	49.5	—	—	●
50	2	R2	67	25.5	50	—	61.5	—	—	●
65	2 1/2	R2 1/2	73	28	61	—	—	80	—	●
80	3	R3	81	32	74	—	—	95	—	●
100	4	R4	92	37	98	—	—	120	—	●

■ 六角片ニップル

HSTN

304(SUS 304)

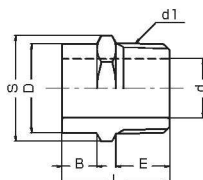

呼び径		ねじ	寸法(mm)					304 在庫			
A (mm)	B (inch)		d1	L	E	B	D		d	S	
									六角	八角	
8	1/4	R1/4	27	12	8	11	7	14	—	—	●
10	3/8	R3/8	29	13	10	16	8.5	17	—	—	●
15	1/2	R1/2	36	16	12	20	12	22	—	—	●
20	3/4	R3/4	38	18	12	26	16	—	27	—	●
25	1	R1	40	20	13	33	22	—	34	—	●
32	1 1/4	R1 1/4	47	22	15	40	31	—	43.5	—	●
40	1 1/2	R1 1/2	49	23	16	48	34	—	49.5	—	●
50	2	R2	56	25.5	16	60	45	—	61.5	—	●