


## PNI 鋼管製管継手 パイプニップル

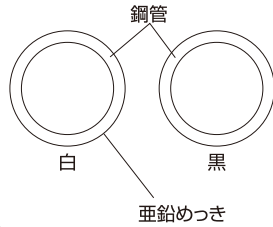


寸法 (B)	品種	バレルニップル	ロングニップル(長さ:mm)														
			50	65	75	90	100	115	125	140	150	175	200	250	300		
1/8	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1/4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3/8	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1/2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3/4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1 1/4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1 1/2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
2 1/2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

● の黒パイプニップルは受注生産品です。  
 ■ 上記表示寸法以外のものについても、ご注文に応じて製作しております。  
 ※給水以外にご使用下さい。

- 水\*
- 湯
- 地下埋設
- ガス
- 消火
- 圧力配管

## PL-PNI 鋼管製管継手 PLパイプニップル

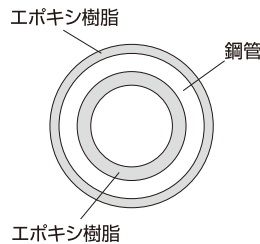


寸法 (B)	品種	バレルニップル	ロングニップル(長さ:mm)														
			50	65	75	90	100	115	125	140	150	175	200	250	300		
1/2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3/4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1 1/4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
1 1/2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
2 1/2	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
3	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

※給水以外にご使用下さい。

- 水\*
- 湯
- 地下埋設
- ガス
- 消火
- 圧力配管

## VB-PNI 水道用硬質塩化ビニルライニング鋼管製 VBパイプニップル

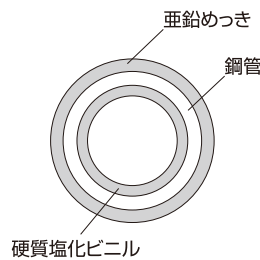

寸法 (B)	品種	バレルニップル	ロングニップル(長さ:mm)				
			50	65	75	100	125
1/2	●	●	●	●	●	●	●
3/4	●	●	●	●	●	●	●
1	●	●	●	●	●	●	●
1 1/4	●	●	●	●	●	●	●
1 1/2	●	●	●	●	●	●	●
2	●	●	●	●	●	●	●
2 1/2	●	●	●	●	●	●	●
3	●	●	●	●	●	●	●
4	●	●	●	●	●	●	●

寸法 (B)	品種	VB(C)-PNI
5	●	●
6	●	●

■他メーカーの管端防食継手(兼用タイプ等)と嵌合する場合は、該当メーカーの施工方法に従ってご使用下さい。

- 水
- 湯
- 地下埋設
- ガス
- 消火
- 圧力配管