



SUS-PNI ステンレス鋼管製 SUSパイプニップル

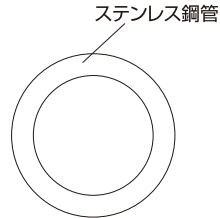

品種 寸法 (B)	バレル ニップル	ロングニップル(長さ:mm)						
		50	65	75	100	125	150	200
1/8	●	●	●	●	●	●	●	●
1/4	●	●	●	●	●	●	●	●
3/8	●	●	●	●	●	●	●	●
1/2	●	●	●	●	●	●	●	●
3/4	●	●	●	●	●	●	●	●
1	●	●	●	●	●	●	●	●
1 1/4	●		●	●	●	●	●	●
1 1/2	●		●	●	●	●	●	●
2	●		●	●	●	●	●	●
2 1/2	●				●	●	●	●
3	●				●	●	●	●
4	●				●	●	●	●

- 水
- 湯
- 地下埋設
- ガス
- 消火
- 圧力配管


SUS-PNI ステンレス鋼管製 SUS片ねじパイプニップル

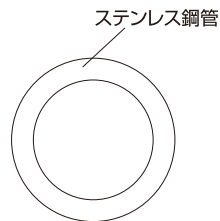

品種 寸法 (B)	片ねじ ニップル	ロングニップル(長さ:mm)					
		50	75	100	125	150	200
1/8	●						
1/4	●	●	●	●	●	●	●
3/8	●	●	●	●	●	●	●
1/2	●	●	●	●	●	●	●
3/4	●	●	●	●	●	●	●
1	●	●	●	●	●	●	●
1 1/4	●		●	●	●	●	●
1 1/2	●		●	●	●	●	●
2	●		●	●	●	●	●
2 1/2	●			●	●	●	●
3	●			●	●	●	●
4	●			●	●	●	●

- 水
- 湯
- 地下埋設
- ガス
- 消火
- 圧力配管

SCH40 PNI 圧力配管用鋼管製 Sch-40 パイプニップル

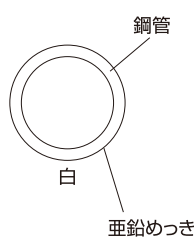

品種 寸法 (B)	バレルニップル
2	●
2 1/2	●
4	●
5	●

- 水*
- 湯
- 地下埋設
- ガス
- 消火
- 圧力配管

*給水以外にご使用下さい。