


90° Large Radius Double-Y

(Abbreviation : WLT)

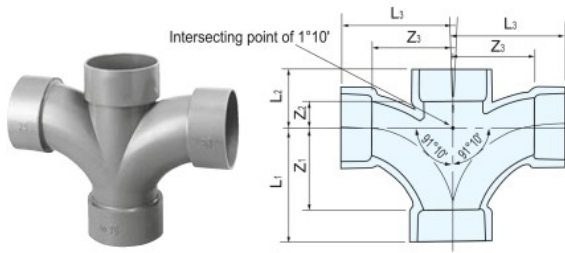

DV Fittings

Code No. 2156


Unit : mm

Nominal Dia.	Z ₁	Z ₂	Z ₃	L ₁	L ₂	L ₃	Standards
65	90	33	90	125	68	125	JIS K 6739
75	100	38	100	140	78	140	
100	128	45	128	178	95	178	
100×75	100	40	110	150	90	150	
Ⓜ125×100	128	52	140	193	117	190	

Note The mark Ⓜ indicates that the product is manufactured by Toeikanki Co., Ltd.

Sockets

(Abbreviation : DS•VU•DS)

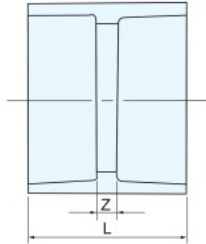

VU-DV Fittings

Code No. 2258

Unit : mm

Nominal Dia.	Z	L	Standards
40	3	47	Ⓜ
50	3	53	AS38
65	3	73	
75	4	84	
100	5	105	
125	5	135	
150	5	165	K-11, AS12
200	5	215	
250	6	270	
300	6	320	
350	12	352	Ⓜ
400	12	412	

DV Fittings


Code No. 2158

Unit : mm

Nominal Dia.	Z	L	Standards
30	3	39	JIS K 6739
40	3	47	
50	3	53	
65	3	73	
75	4	84	
100	4	104	
125	4	134	
150	4	164	

Increaser

(Abbreviation : IN•VU•IN)

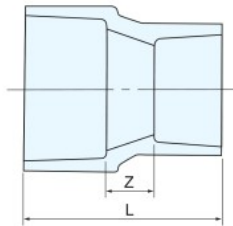

VU-DV Fittings

Code No. 2259

Unit : mm

Nominal Dia.	Z	L	Standards
50×40	20	67	Ⓜ
75×50	25	90	AS38
75×65	25	100	
100×50	30	105	
100×65	30	115	
100×75	30	120	
125×100	35	150	
150×100	40	170	
150×125	40	185	
200×100	45	203	Ⓜ
200×125	45	218	
200×150	50	235	
250×200	60	290	

DV Fittings

Code No. 2159

Unit : mm

Nominal Dia.	Z	L	Standards	
40×30	20	60	JIS K 6739	
50×30	20	63		
50×40	20	67		
65×40	20	77		
65×50	20	80		
75×40	25	87		
75×50	25	90		
75×65	25	100		
100×40	30	102		
100×50	30	105		
100×65	30	115		
100×75	30	120		
125×65	35	135		Ⓜ
125×75	35	140		JIS K 6739
125×100	35	150		
150×75	40	160	Ⓜ	
150×100	40	170	JIS K 6739	
150×125	40	185		