


32A Wheel

32A is an exceedingly tough, sharp mono-crystalline abrasive, and is suitable for grinding hardened heat sensitive steels. It grinds with exceptional cool, free-cutting, and good corner holding, which contributes to long wheel life.

[Applications] Grinding tungsten carbide, alloy cast iron, non-ferrous metals, and non-metal (such as rubber, and plastic).

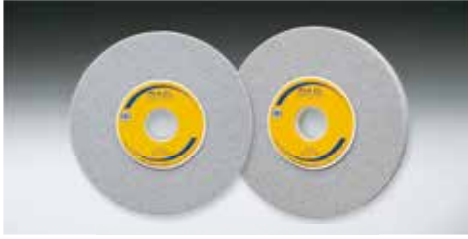

Item No.	Size (mm)			Spec.	M.O.S.	Packing	Remarks
	O.D.	Thk.	Hole				
S120005	150	13	31.75	32A 60 J	33	20	
S120014	180	6.4	31.75	32A 60 J	40	20	
S120020	180	6.4	31.75	32A 80 K	40	20	
S120024	180	6.4	31.75	32A 100 K	40	20	
S120572	180	6.4	31.75	32A 120 K	40	20	
S120054	180	10	31.75	32A 46 J	40	20	
S120059	180	10	31.75	32A 60 I	40	20	
S120061	180	10	31.75	32A 60 J	40	20	
S120065	180	10	31.75	32A 80 J	40	20	
S120075	180	13	31.75	32A 46 H	40	20	
S120077	180	13	31.75	32A 46 I	40	20	
S120079	180	13	31.75	32A 46 J	40	20	
S120081	180	13	31.75	32A 46 K	40	20	
S120088	180	13	31.75	32A 60 J	40	20	
S120181	205	13	31.75	32A 46 H	40	20	
S120184	205	13	31.75	32A 46 J	40	20	
S120187	205	13	31.75	32A 60 I	40	20	
S120188	205	13	31.75	32A 60 J	40	20	
S120192	205	13	31.75	32A 80 J	40	20	
S120194	205	13	31.75	32A 80 K	40	20	
S120202	205	13	31.75	32A 120 J	40	20	
S120239	205	19	31.75	32A 46 H	40	10	
S120243	205	19	31.75	32A 46 J	40	10	
S120247	205	19	31.75	32A 60 H	40	10	
S120249	205	19	31.75	32A 60 I	40	10	
S120250	205	19	31.75	32A 60 J	40	10	
S120254	205	19	31.75	32A 80 H	40	10	
S120257	205	19	31.75	32A 80 J	40	10	
S120269	205	19	50.8	32A 46 H	40	10	
S120271	205	19	50.8	32A 46 I	40	10	
S120272	205	19	50.8	32A 46 J	40	10	
S120274	205	19	50.8	32A 60 H	40	10	
S120275	205	19	50.8	32A 60 I	40	10	
S120277	205	19	50.8	32A 60 J	40	10	

Item No.	Size (mm)			Spec.	M.O.S.	Packing	Remarks
	O.D.	Thk.	Hole				
S120283	205	19	50.8	32A 80 K	40	10	
S120319	305	25	76.2	32A 46 H	33	5	
S120322	305	25	76.2	32A 46 J	33	5	
S120345	305	32	76.2	32A 46 H	33	3	
S120347	305	32	76.2	32A 46 I	33	3	
S120349	305	32	76.2	32A 46 J	33	3	
S120353	305	32	76.2	32A 60 I	33	3	
S120354	305	32	76.2	32A 60 J	33	3	
S120359	305	32	127	32A 46 H	33	3	
S120366	305	32	127	32A 60 J	33	3	
S120375	305	38	76.2	32A 46 H	33	3	
S120381	305	38	76.2	32A 60 J	33	3	
S120388	305	38	127	32A 46 H	33	3	
S120392	305	38	127	32A 46 J	33	3	
S120394	305	38	127	32A 60 H	33	3	
S120398	305	38	127	32A 60 J	33	3	
S120410	305	50	127	32A 46 H	33	2	
S120411	305	50	127	32A 46 I	33	2	
S120426	355	25	76.2	32A 46 H	33	3	
S120438	355	32	127	32A 60 J	33	2	
S120441	355	38	76.2	32A 46 H	33	2	
S120443	355	38	76.2	32A 46 J	33	2	
S120444	355	38	76.2	32A 60 J	33	2	
S120447	355	38	127	32A 46 H	33	2	
S120449	355	38	127	32A 46 I	33	2	
S120451	355	38	127	32A 46 J	33	2	
S120453	355	38	127	32A 46 K	33	2	
S120457	355	38	127	32A 60 H	33	2	
S120459	355	38	127	32A 60 I	33	2	
S120461	355	38	127	32A 60 J	33	2	
S120463	355	38	127	32A 60 K	33	2	
S120467	355	38	127	32A 80 J	33	2	
S120473	355	50	127	32A 46 H	33	2	
S120477	355	50	127	32A 46 J	33	2	
S120480	355	50	127	32A 60 H	33	2	
S120484	355	50	127	32A 60 J	33	2	
S120499	405	50	127	32A 60 J	33	2	
S120503	405	50	127	32A 80 I	33	2	
S120509	405	50	152.4	32A 60 J	33	2	
S120519	510	50	127	32A 46 H	33	1	

Depressed Center Wheel

Flexible Depressed Center Wheel

Cutting-off Wheel

Coated Abrasives/ Non-Woven Abrasives

Alumina Fiber Stones

Mounted Wheel

Straight Wheel

Other Shapes

Diamond /CBN Wheel

Truing & Dressing Tools

Grinding & Cutting Fluids

Filter

Safety Products