


新製品

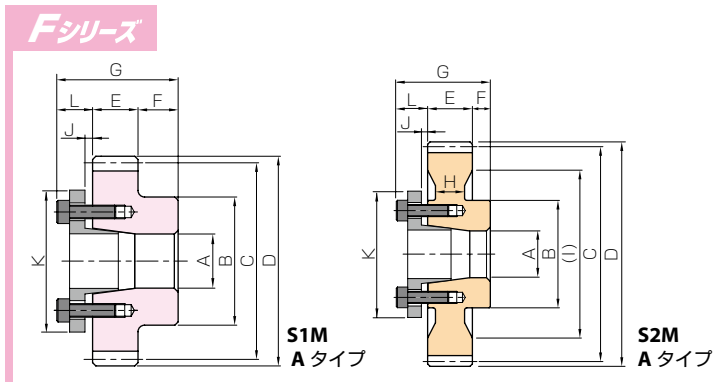

Fシリーズは**カタログ記号+F+穴径+A**にてご注文ください。

\*寸法表の背景色はFシリーズの形状図を表しております。

軸穴径 A	ご注文数 1~4個のFシリーズ単価 (円)														
	10	12	14	15	16	17	18	19	20	22	25	28	30	32	35
SS1.5-26 F 穴径 A	6,150														
SS1.5-27 F 穴径 A	6,180														
SS1.5-28 F 穴径 A	6,200	6,200													
SS1.5-29 F 穴径 A	6,220	6,220													
SS1.5-30 F 穴径 A	6,250	6,250													
SS1.5-32 F 穴径 A	6,320	6,320	6,620	6,250	6,250										
SS1.5-34 F 穴径 A	6,360	6,360	6,660	6,290	6,290	6,430									
SS1.5-35 F 穴径 A	6,430	6,430	6,730	6,360	6,360	6,500	6,500								
SS1.5-36 F 穴径 A	6,450	6,450	6,750	6,380	6,380	6,520	6,520	7,180							
SS1.5-38 F 穴径 A		6,580	6,880	6,510	6,510	6,650	6,650	7,310							
SS1.5-40 F 穴径 A		6,590	6,890	6,520	6,520	6,660	6,660	7,320							
SS1.5-42 F 穴径 A		6,740	7,040	6,670	6,670	6,810	6,810	7,470							
SS1.5-44 F 穴径 A		6,870	7,170	6,800	6,800	6,940	6,940	7,600							
SS1.5-45 F 穴径 A		6,880	7,180	6,810	6,810	6,950	6,950	7,610							
SS1.5-46 F 穴径 A		6,930	7,230	6,860	6,860	7,000	7,000	7,660							
SS1.5-48 F 穴径 A		7,040	7,340	6,970	6,970	7,110	7,110	7,770							
SS1.5-50 F 穴径 A		7,070	7,370	7,000	7,000	7,140	7,140	7,800							
SS1.5-52 F 穴径 A				7,170	7,170	7,310	7,310	7,980							
SS1.5-54 F 穴径 A				7,320	7,320	7,460	7,460	8,130							
SS1.5-55 F 穴径 A				7,320	7,320	7,460	7,460	8,130							
SS1.5-56 F 穴径 A				7,340	7,340	7,480	7,480	8,150							
SS1.5-58 F 穴径 A				7,480	7,480	7,620	7,620	8,290							
SS1.5-60 F 穴径 A				7,530	7,530	7,670	7,670	8,340							
SS1.5-62 F 穴径 A				7,710	7,710	7,850	7,850	8,520	8,520						
SS1.5-64 F 穴径 A				7,980	7,980	8,120	8,120	8,790	8,790						
SS1.5-65 F 穴径 A				7,990	7,990	8,130	8,130	8,800	8,800						
SS1.5-66 F 穴径 A				8,060	8,060	8,200	8,200	8,870	8,870						
SS1.5-68 F 穴径 A				8,080	8,080	8,220	8,220	8,890	8,890						
SS1.5-70 F 穴径 A				8,090	8,090	8,230	8,230	8,900	8,900						
SS1.5-72 F 穴径 A				8,360	8,360	8,500	8,500	9,170	9,170						
SS1.5-75 F 穴径 A				8,460	8,460	8,600	8,600	9,270	9,270	9,270	9,550	9,800			
SS1.5-76 F 穴径 A				8,490	8,490	8,630	8,630	9,300	9,300	9,300	9,580	9,830			
SS1.5-80 F 穴径 A				8,820	8,820	8,960	8,960	9,630	9,630	9,630	9,910	10,160			
SS1.5-84 F 穴径 A				9,220	9,220	9,360	9,360	10,030	10,030	10,030	10,310	10,560			
SS1.5-85 F 穴径 A				9,230	9,230	9,370	9,370	10,040	10,040	10,040	10,320	10,570			
SS1.5-88 F 穴径 A				9,290	9,290	9,430	9,430	10,100	10,100	10,100	10,380	10,630			
SS1.5-90 F 穴径 A				9,730	9,730	9,870	9,870	10,530	10,530	10,530	10,810	11,060			
SS1.5-95 F 穴径 A				9,860	9,860	10,000	10,000	10,660	10,660	10,660	10,940	11,190			
SS1.5-100 F 穴径 A				10,420	10,420	10,560	10,560	11,220	11,220	11,220	11,500	11,760			
SS1.5-120 F 穴径 A				12,480	12,480	12,620	12,620	13,290	13,290	13,290	13,570	13,820	14,020	14,200	14,410
SS1.5-150 F 穴径 A									15,370	15,370	15,650	15,900	16,100	16,290	16,490

ご注文数 5~20 個までの単価は巻末の価格表又は Web をご覧ください。

- (Fシリーズの注意)
- ①受注生産品のため、受注後**実働 2 日以内 (受注日除く)** でメーカー完成となります。
  - ②対応数は 1~20 個です。20 個を超える場合は、別途お見積りとさせていただきます。
  - ③締結部品と歯車の追加工部は黒染をしていません。