

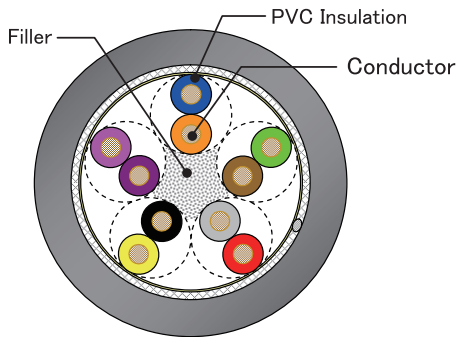


TPPE/ETFE-insulated robot cable series
 Globally compliant power cable series
 Twisted-pair cable series
 AWG28 cable series
 Modular cables
 Photovoltaic power system cables
 Special-purpose cables
 Technical data

Construction figure

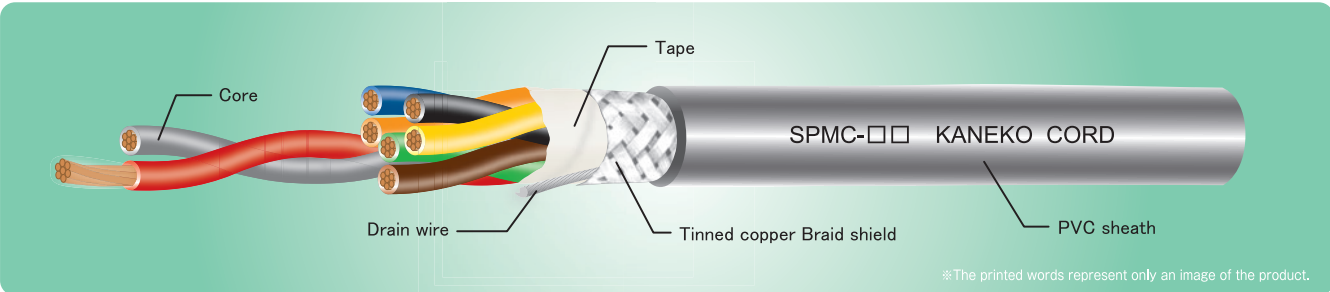

Features graph

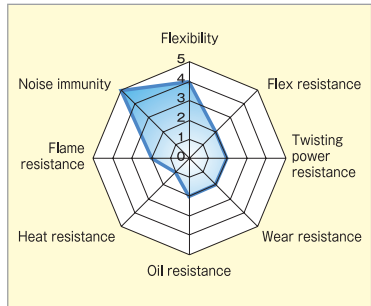

Marking

- SPMC-□□ KANEKO CORD (Marking color: White)

Characteristics

- 30/0.08 annealed copper conductor is used. Realized high flexibility.
- Twisted pair structure. Good performance of signal, and noise resistance.
- Shield braid is effective EMC measure.

Use

- for Electronic equipment.

Rating

Temp.	60°C
Voltage	100V MAX

Electrical Characteristics

Conductor resistance	Insulation resistance	Withstand Voltage
(Ω/km)	(MΩ/km)	(V/1min)
137MAX	10MIN	AC 500V