


ティーハンドル TH-N-L, TH-N

T Handles TH-N-L, TH-N

RoHS指令適合品




TH-N-L

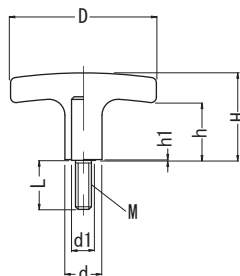

材表 ノブ knob : 艶消し黒色ナイロン樹脂PA6 (ガラス繊維強化)
Glass-fiber Nylon resin
ネジ screw : 鋼材SUM22L・三価クロメート Steel Trivalent Chromate



TH-N

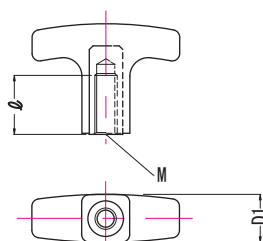

材 ノブ knob : 艶消し黒色ナイロン樹脂PA6 (ガラス繊維強化)
Glass-fiber Nylon resin
ネジ screw : 黄銅C3604B brass

Unit : mm

品番	D	M	L	d	H	D1	d1	h	h1	(g)
TH-40N ×20	40	M 6×P1.0	20	13×13	30	13	9	20.0	0.3	17
TH-55NA ×20	55	M 8×P1.25		14×14	33	14	10	22.0		28
TH-67N ×25	67		25	16×16	37	16	11	25.0		38
TH-80N ×30	80	M10×P1.5	30	20×20	41	20	13	26.0		58
TH-95N ×30	95	M12×P1.75		21×21	45	21	13	28.5		68

Unit : mm

品番	D	M	φ	d	H	D1	d1	h	h1	(g)
TH-40NB	40	M 6×P1.0	16	13×13	30	13	9	20.0	0.3	16
TH-55N	55		18	14×14	33	14	10	22.0		27
TH-67N	67	M 8×P1.25	20	16×16	37	16	11	25.0		37
TH-80NB	80	M10×P1.5	25	20×20	41	20	13	26.0		56
TH-95N	95	M12×P1.75		21×21	45	21	13	28.5		66

注意事項 使用温度 max80°C min-20°C