

ナールドナット KNTA-sus KNTA-B, KNTB-B KNTA, KNTB



Knurled Nuts KNTA-sus
Knurled Nuts KNTA-B, KNTB-B
Knurled Nuts KNTA, KNTB




KNTA-sus 材 ステンレスSUS303
Stainless



KNTA 材 鋼材S45C Steel
KNTB 表 クロムメッキ Chrome plated



KNTA-B 材 鋼材S45C Steel
KNTB-B 表 黒色四三酸化鉄皮膜
Black oxide finish

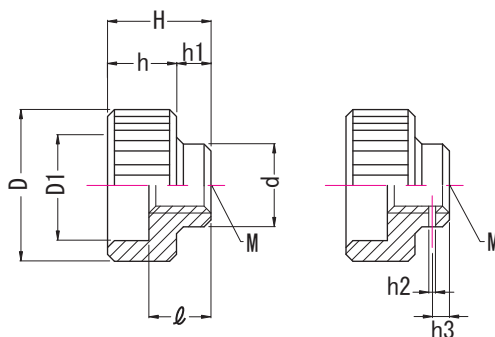

止め穴なしタイプ

Unit : mm

品番	品番	品番	M	φ	D	D1	d	H	h	h1	(g)
KNTA-5-sus	KNTA-5-B	KNTA-5	M 5×P0.8	7	20	15	14	12	8	4	16
KNTA-6-sus	KNTA-6-B	KNTA-6	M 6×P1.0	8	24	18	18	14	10	4	27
KNTA-8-sus	KNTA-8-B	KNTA-8	M 8×P1.25	10	30	24	20	17	12	5	50
KNTA-10-sus	KNTA-10-B	KNTA-10	M10×P1.5	12	36	30	28	20	14	6	83
KNTA-12-sus	KNTA-12-B	KNTA-12	M12×P1.75	14	40	34	32	24	16	8	123

止め穴付タイプ

Unit : mm

品番	品番	M	φ	D	D1	d	H	h	h1	h2	h3	(g)
KNTB-5-B	KNTB-5	M 5×P0.8	7	20	15	14	12	8	4	1.5	2.5	16
KNTB-6-B	KNTB-6	M 6×P1.0	8	24	18	16	14	10	4	2.0	3.0	27
KNTB-8-B	KNTB-8	M 8×P1.25	10	30	24	20	17	12	5	2.0	3.0	50
KNTB-10-B	KNTB-10	M10×P1.5	12	36	30	28	20	14	6	3.0	4.0	83
KNTB-12-B	KNTB-12	M12×P1.75	14	40	34	32	24	16	8	4.0	4.0	123