

# 鋼製握り（二面取りタイプ） A

Steel Grips (Two phases cut Type) A

RoHS指令適合品

# 鋼製握り（差込みタイプ） B


Steel Grips (Insertion Type) B



A



B

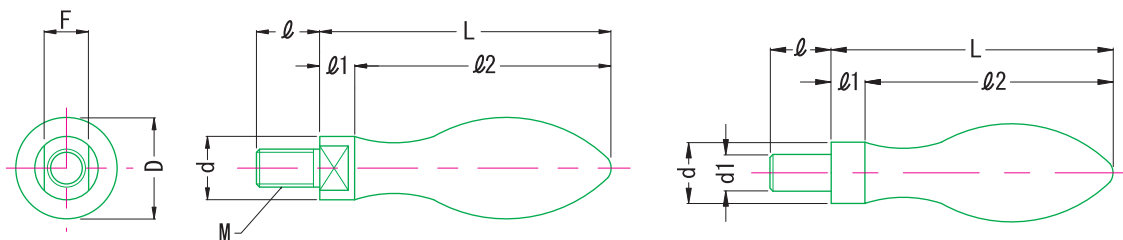

材 鋼材SUM22 Steel

表 クロムメッキ Chrome plated

Unit : mm

品番	D	M	l	L	l1	l2	d	F	(g)
A-20	20	M 8×P1.25	15	64	8	56	13	11	90
A-25	25	M10×P1.5	18	80	10	70	16	14	175
A-32	32	M12×P1.75	20	100	13	87	20	17	355
A-36	36	M16×P2.0	22	112	14	98	22	19	525

Unit : mm

品番	D	d1	l	L	l1	l2	d	(g)
B-10	10	4	9	32	4	28	7	12
B-13	13	5	10	40	5	35	8	25
B-16	16	6	13	50	7	43	10	45
B-20	20	8	15	64	8	56	13	90
B-25	25	10	18	80	10	70	16	175
B-32	32	12	20	100	13	87	20	355
B-36	36	16	22	112	14	98	22	525

グリップ