

ベアリングホルダーセット インローダブル直接取付タイプ 四角型

Bearing Holder Set Inlay double direct inatallation type Square style


2個のベアリングを使用している為、耐荷重の必要な箇所に最適です。

RoHS指令適合品



DSM

- H 鋼材S45C
- H 鉛フリー無電解ニッケルメッキ
Electroless Nickel plating
- B ベアリング鋼 Steel

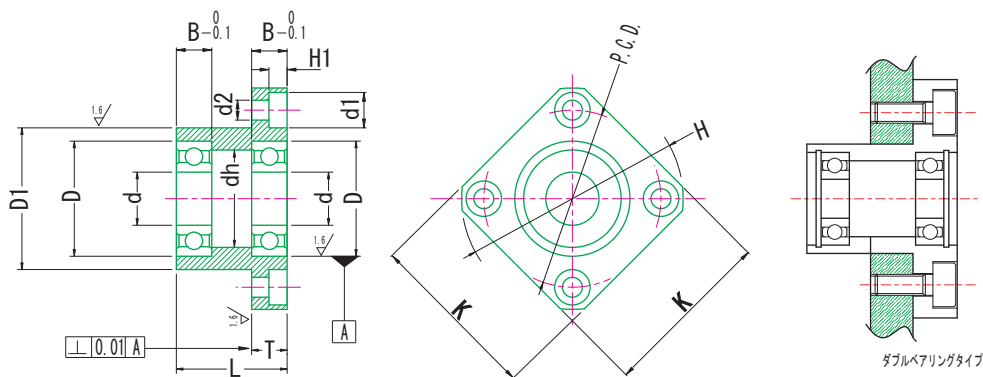

寸法表

Unit : mm

品番	ベアリング	L	d	D (H7) 許容差	B	H	K	T	dh	D1 (g7) 許容差	P.C.D.	d1	d2	H1	(g)	
DSM	6900ZZ	25	22	+0.021 0	6	45	36	8	19	27	-0.007 -0.028	35	8.0	4.5	4.1	121
	6000ZZ	25	26		8	50	39		22	32	-0.009	40				176
	6200ZZ	30	30		9	54	42		24	36	-0.034	44				263
	6901ZZ	25	24	+0.025 0	6	48	38	10	21	30	-0.007 -0.028	38	9.5	5.5	5.1	144
	6001ZZ	25	28		8	52	40		24	34	42	184				
	6201ZZ	30	32		10	56	43		26	38	46	281				
	6902ZZ	25	28	+0.025 0	7	57	45	11	25	35	-0.009 -0.034	45	11.0	6.6	6.1	204
	6002ZZ	30	32		9	60	46		28	38		48				272
	6202ZZ	35	35		11	64	49		29	42		52				395
	6904ZZ	35	37	+0.025 0	9	69	54	13	34	45	-0.010 -0.040	56	14.0	9.0	8.1	394
	6004ZZ	40	42		12	77	59		36	50		64				486
	6204ZZ	45	47		14	81	62		40	54		68				794
	6005ZZ	40	47	+0.030 0	12	88	67	13	41	54	-0.010 -0.040	72	9.0	8.1	720	
	6205ZZ	45	52		15	94	72		45	60		78			1,012	
	6006ZZ	40	55		13	96	73		48	62		80			914	
	6206ZZ	50	62	+0.030 0	16	104	79	13	55	70	-0.010 -0.040	88	14.0	9.0	8.1	1,396
	6007ZZ	50	62		14	104	79		55	70		88				1,260
	6008ZZ	60	68		15	114	86		60	78		96				1,700