


Multi-rail terminal block


TX, TXU and TXW Series

Standard type

Application			Type name	Number of contents	External dimensions (mm)				General mass per pole (g)	
					A	B	C	D		
Terminal unit										
600V	1.25mm <sup>2</sup> [15A]	M3×6± screw type	TX 7	60P	38	29	7.3	6	6	
	2mm <sup>2</sup> [20A]	M3×8± screw type	TX 10 SM3	60P			8	6.7	6.5	
		M3.5×8± screw type	TX 10 S	60P			9.5	8	8	
		M3.5×8± screw type	TX 10	60P						
	5.5mm <sup>2</sup> [40A]	M4×10± screw type	TX 20	60P	46	34	12	9.7	11	
	8mm <sup>2</sup> [50A]	M5×12± screw type	TX 30	30P			14.5	12.5	22	
	14mm <sup>2</sup> [80A]	M5×12± screw type	TX 50	30P	54	38	37	15	25	
	22mm <sup>2</sup> [90A]	M6×12± with round washer	TX 60	10P			19.5	17	37	
	38mm <sup>2</sup> [130A]	M8×14+ hexagonal bolt	TX 100	6P	72	45	27	24	83	
	60mm <sup>2</sup> [175A]	M8×16+ hexagonal bolt	TX 150	6P	76	51	28	25	96	
	100mm <sup>2</sup> [240A]	M10×12+ hexagonal bolt	TX 200	3P	82	57.5	39	31	175	
	150mm <sup>2</sup> [310A]	M10×20+ hexagonal bolt	TX 300	3P	86	62.5	46	37.5	215	
	200mm <sup>2</sup> [400A]	M12×25 hexagonal bolt	TX 400	3P	120	73.5	62	52	382	
	150mm <sup>2</sup> ×2 [500A]	M16×40 stud	TX 600	3P						
200mm <sup>2</sup> [400A]			86.5	64						650
250mm <sup>2</sup> [500A]										
325mm <sup>2</sup> [600A]										
End plate										
For TX 7 to TX20			TXA 1	10 pieces	38	29	Thickness 3		2.5	
For TX 30			TXA 3	10 pieces	46	34			4	
For TX 50			TXA 5	10 pieces	49	37			5	
For TX 60			TXA 6	5 pieces	54	38	Thickness 3.5		5.5	
For TX 100			TXA 10	5 pieces	72	45	Thickness 4		11	
For TX 150			TXA 15	5 pieces	76	51			14	
Insulation barrier										
For TX 600 (Dimension A 240mm in setting)			TXH 60	2 pieces	—	—	—		12	

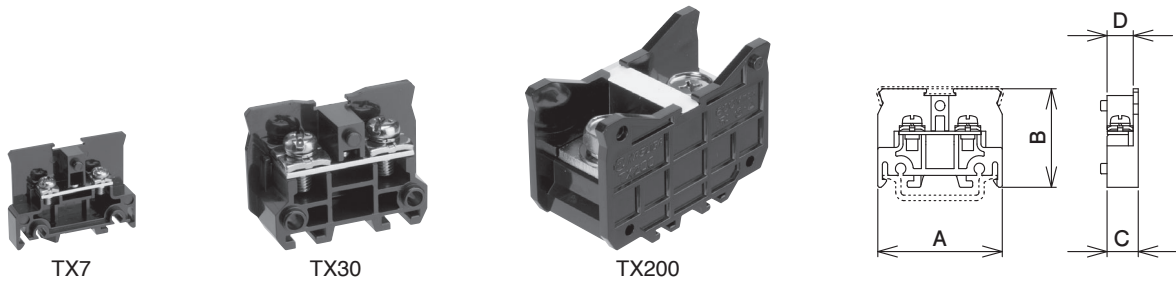

TX series

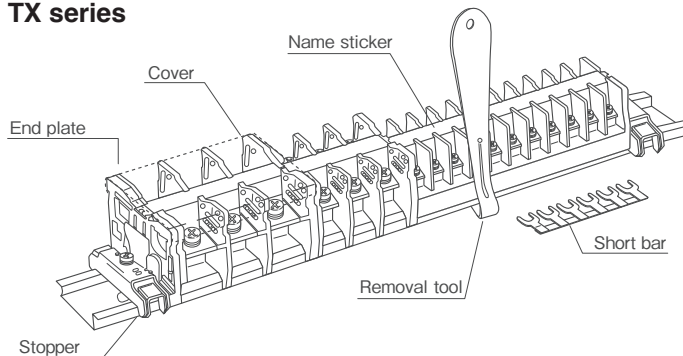

Line-up  
Terminal Blocks  
Clutch Lock  
Terminal Blocks  
PLC Interface  
Terminal Blocks  
Rail Type  
Terminal Blocks  
Assembly  
Terminal Blocks  
Special Purpose  
Terminal Blocks  
Terminal  
Block Accessories