



End plate

This is used for terminal of assembled terminal unit. When two sheets are used for both ends, they also work as stopper of sticker. Furthermore, it is also possible to use one sheet for one side by bending and removing the lug for pressing sticker.

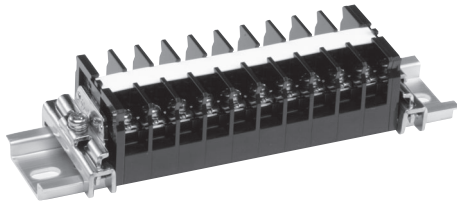

When two sheets are used for both sides

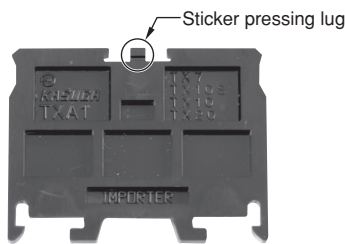

TXA1

(for TR Series)

Use one sheet for the terminal of assembled terminal unit. However, it is not necessary for TR200 and TR400. As the N type has no groove for leading name sticker, it is possible to use two sheets for both ends to use them as stopper of sticker too.

(for TW Series)

The end plate is used for terminal of assembled terminal unit. Furthermore, it also works as a stopper of name sticker. Each sheet for right and left is one set.

Type name	Applicable unit	Thickness (mm)	General mass (g)	Number of contents
TXA 1	TX7 to TX20	3	2.5	10 pieces
TXA 3	TX30	3	4	10 pieces
TXA 5	TX50	3	5	10 pieces
TXA 6	TX60	3.5	5.5	5 pieces
TXA 10	TX100	4	11	5 pieces
TXA 15	TX150, TXW150	4	14	5 pieces
TXUA 1	TXU7 to TXU20	3	2.5	10 pieces
TXUA 3	TXU30	3	4.5	10 pieces
TXUA 5	TXU50	3	5	10 pieces
TXUA 6	TXU60	3.5	6	5 pieces
TXUA 10	TXU100	4	14	5 pieces
TXFA 1	TXF10, TXF10N, TXS20	3.5	10	10 pieces
TXSUA 20	TXSU20	3	5	10 pieces
TXWA 10	TXW100R, TXW100DR	4	14	5 pieces
TXWA 20	TXW200R, TXW200DR	4	17	5 pieces
TXWA 40	TXW400	5	30	3 pieces
TTA 1 SK	TT10SK, TT10SUK	8 with two sheets	12.7	5 sets of A/B
TTA 2 K	TT20K, TT20UK	11 with two sheets	22	5 sets of A/B
TTJA 8N	TTJ8N, TTJ8NU	8 with two sheets	11	5 sets of A/B
TXJA 7	TXJ7	2.5	1.5	10 pieces
TXJA 8	TXJ8	2.5	2	10 pieces
TFPA 20	TFP15, TFP20	3	2.5	10 pieces
TFPA 40	TFP40	3	5	10 pieces
TFPA 80	TFP80	3	7	10 pieces
TTFPA 20	TTFP203, TTFP2035	8 with two sheets	13	5 sets of A/B
TTGA 20	TTG203, TTG2035, TTG20U3, TTG20U35	8 with two sheets	13	5 sets of A/B
TTGA 40	TTG40, TTG40U	10.5 with two sheets	22	5 sets of A/B

Type name		Applicable unit	Thickness (mm)	General mass (g)	Number of contents
There is a groove for sticker	There is no groove for sticker				
TRA 1 K	TRA 1 NK	TR10K, TR10SK	2	2	10 pieces
TRA 2 K	TRA 2 NK	TR20K	2	2	10 pieces
TRA 3 K	TRA 3 NK	TR30K	3	2.5	10 pieces
TRA 6 K	TRA 6 NK	TR60K	3	5	5 pieces
TRA 10 K	TRA 10 NK	TR100K	3.5	10	5 pieces

Type name	Product name	General mass (g)	Number of contents
TWA 10B	For TW 10B	4	5 pairs
TWA 15B	For TW 15B	4.5	
TWA 16B	For TW 16B	5.5	
TWA 20B	For TW 20B	4	
TWA 25B	For TW 25B	4.5	
TWA 26B	For TW 26B	7	
TWA 30B	For TW 30B	9	
TWA 50B	For TW 50B	11	
TWA 16BC	For TW 16BC	5.5	
TWA 26BC	For TW 26BC	10	
TWA 16BCB	For TW 16BCB	5.5	
TWA 26BCB	For TW 26BCB	10	
TWA 15D	For TW 15D	5	
TWA 16D	For TW 16D	6	
TWA 25D	For TW 25D, TW 25DE	7	
TWA 26D	For TW 26D, TW 26DE	7.5	
TWA 35D	For TW 35D	9	
TWA 36D	For TW 36D	11	
TTWA 20D	For TTW 20D	11	
TWA 25F	For TW 25F	12	
TWYA 10	For TWY 10	6	
TWYA 16	For TWY 16	9	
TWEA 20	For TWEU 20	7	

Note: End plate general mass is total of right and left 2 plates (1 pair).

Line-up
Clutch Lock
Terminal Blocks
PLC Interface
Terminal Blocks
Rail Type
Terminal Blocks
Assembly
Terminal Blocks
Special Purpose
Terminal Blocks
Terminal Block Accessories